




Extract from the online catalog

UM 45-D50SUB/B

Order No.: 2962764

The illustration shows the version UM 45-D37SUB/S

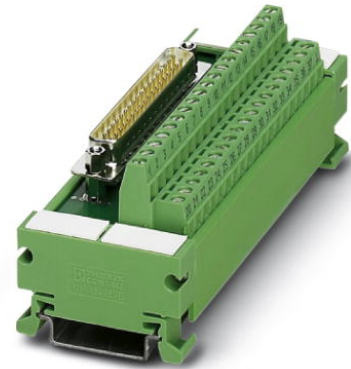


<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=2962764>

VARIOFACE module, with screw connection and D-subminiature socket strip, for assembly on NS 35/7.5, 50 positions (no consecutive numbering)

Commercial data	
EAN	4017918087425
Pack	1 pcs.
Customs tariff	85366990
Weight/Piece	0.1816 KG
Catalog page information	Page 250 (IF-2007)

Product notes

WEEE/RoHS-compliant since:
08/11/2006



<http://www.download.phoenixcontact.com>
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

Technical data

General data	
Nominal voltage U_N	125 V AC/DC
Max. current carrying capacity per branch	2.5 A
	1.5 A (with even load on all branches)
Number of positions	50

UM 45-D50SUB/B Order No.: 2962764
http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=2962764

Width	156 mm
Height	42 mm
Depth	45 mm
Ambient temperature (operation)	-20 °C ... 50 °C
Ambient temperature (storage/transport)	-20 °C ... 70 °C
Test voltage	800 V (50 Hz, 1 min)
Mounting position	Any
Standards/regulations	IEC 60664
	DIN VDE 110
Pollution degree	2
Surge voltage category	II

Connection data

Connection 1	PCB connection
Connection in acc. with standard	IEC / EN
Type of connection	Screw connection
Conductor cross section solid min.	0.14 mm ²
Conductor cross section solid max.	1.5 mm ²
Conductor cross section stranded min.	0.14 mm ²
Conductor cross section stranded max.	1.5 mm ²
Conductor cross section AWG/kcmil min.	26
Conductor cross section AWG/kcmil max	16
Stripping length	6 mm
Screw thread	M3
Connection 2	D-SUB connection
Type of connection	Pluggable

Certificates / Approvals



Certification CUL, GOST, UL

CUL


Nominal voltage U_N	125 V
Nominal current I_N	2.5 A

UM 45-D50SUB/B Order No.: 2962764
<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=2962764>

AWG/kcmil	30-14
UL	
Nominal voltage U_N	125 V
Nominal current I_N	2.5 A
AWG/kcmil	30-14

Diagrams/Drawings

Circuit diagram

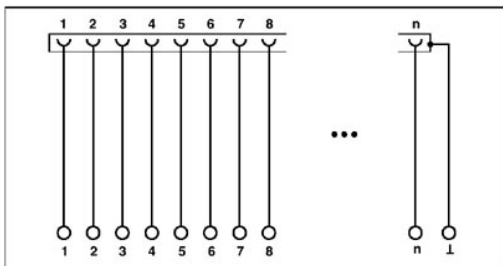

onlinecomponents.com

UM 45-D50SUB/B Order No.: 2962764
<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=2962764>

Address

PHOENIX CONTACT Deutschland GmbH
Flachmarktstr. 8
32825 Blomberg, Germany
Phone +49 5235 3 12000
Fax +49 5235 3 41200
<http://www.phoenixcontact.de>



© 2010 Phoenix Contact
Technical modifications reserved;

onlinecomponents.com