




Extract from the online catalog

# UK 6 N OG

Order No.: 3003305

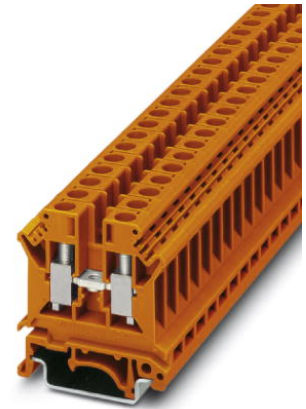

<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=3003305>

Feed-through modular terminal block, Type of connection: Screw connection, Number of positions: 1, Cross section: 0.2 mm<sup>2</sup> - 10 mm<sup>2</sup>, AWG 24 - 8, Width: 8.2 mm, Color: orange, Mounting type: NS 35/7,5, NS 35/15



Commercial data	
EAN	4017918240417
Pack	50 pcs.
Customs tariff	85369010
Weight/Piece	0.01401 KG

**Product notes**

WEEE/RoHS-compliant since: 01/01/2003

<http://www.download.phoenixcontact.com>  
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

## Certificates / Approvals



Certification

CCA, CUL, DNV, GL, KEMA, UL

UK 6 N OG Order No.: 3003305

<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=3003305>

Certification Ex:

FM, GL-EX, IECEx, KEMA-EX

**CUL**

Nominal voltage $U_N$	600 V
Nominal current $I_N$	50 A
AWG/kcmil	26-8

**UL**

Nominal voltage $U_N$	600 V
Nominal current $I_N$	50 A
AWG/kcmil	26-8

**Diagrams/Drawings**

Approbationslogos (EX-Bereich)



UK 6 N OG Order No.: 3003305

<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=3003305>

---



onlinecomponents.com

UK 6 N OG Order No.: 3003305

<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=3003305>

---

**Address**

PHOENIX CONTACT Deutschland GmbH  
Flachmarktstr. 8  
32825 Blomberg, Germany  
Phone +49 5235 3 12000  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.de>



© 2010 Phoenix Contact  
Technical modifications reserved;

onlinecomponents.com