
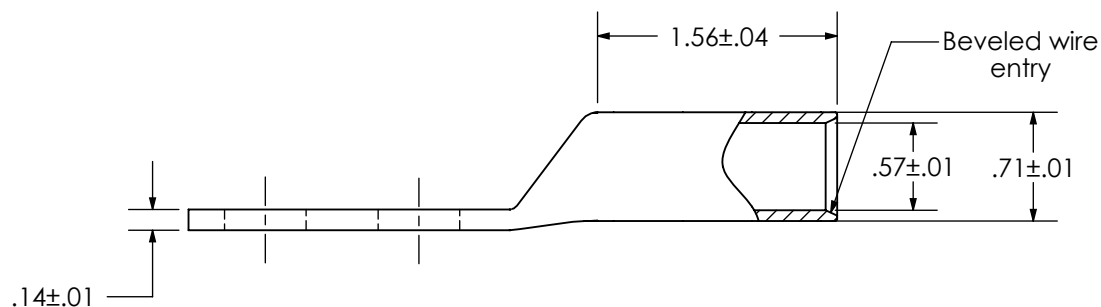


Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	4/0 AWG
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	1-5/8 in.
Stud Size	1/2 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	PURPLE
Panduit Die Index No. on Barrel	P54
Alternate Industry Die Index No. () on Barrel	(15)

LISTED
Wire Connector

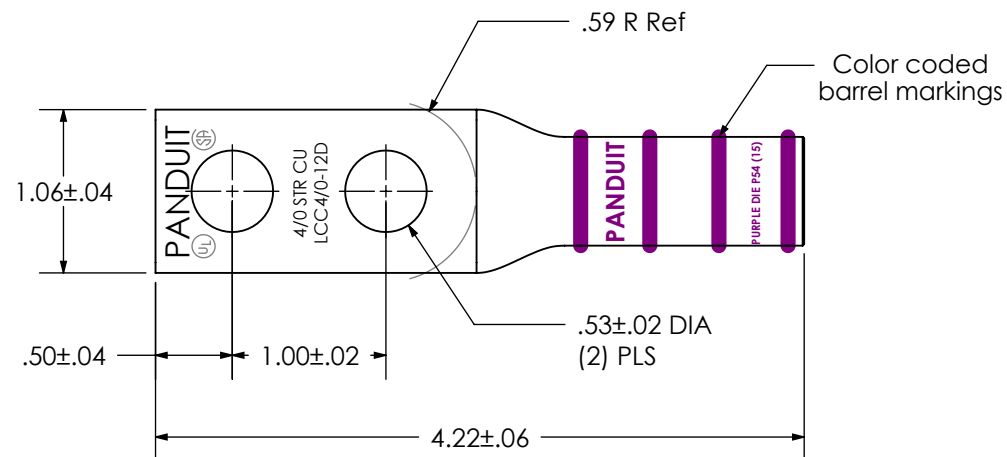

								PANDUIT CORP. TINLEY PARK, ILLINOIS	
								LCC4/0-12D-X Copper Lug - Two-Hole, Long Barrel	
01	7/12	JHNU	JHNU	REMOVED NAVY NUMBER	N10883DE-LCC4/0-12D-CUST	RGB	RGB		
REV	DATE	BY	CHK	DESCRIPTION	ECN	-R	SUP	SCALE N/A	DRAWING NO / CAD FILE LCC4_0-12D-CUST