
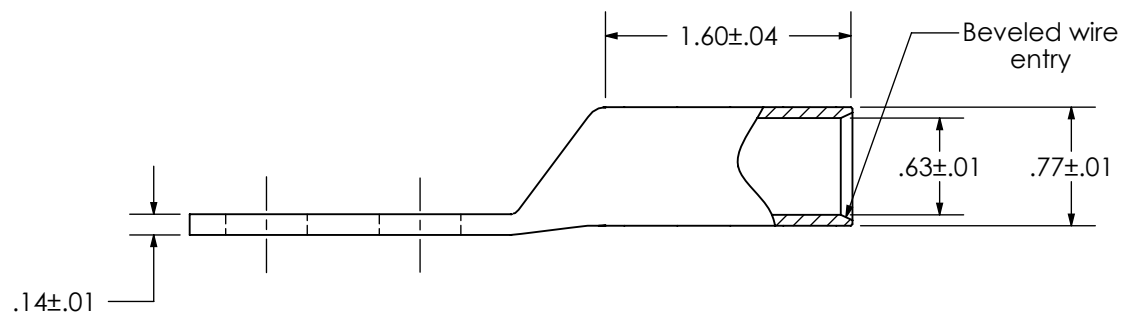


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	250 kcmil
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	1-11/16 in.
Stud Size	1/2 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	YELLOW
Panduit Die Index No. on Barrel	P62
Alternate Industry Die Index No. () on Barrel	(16)

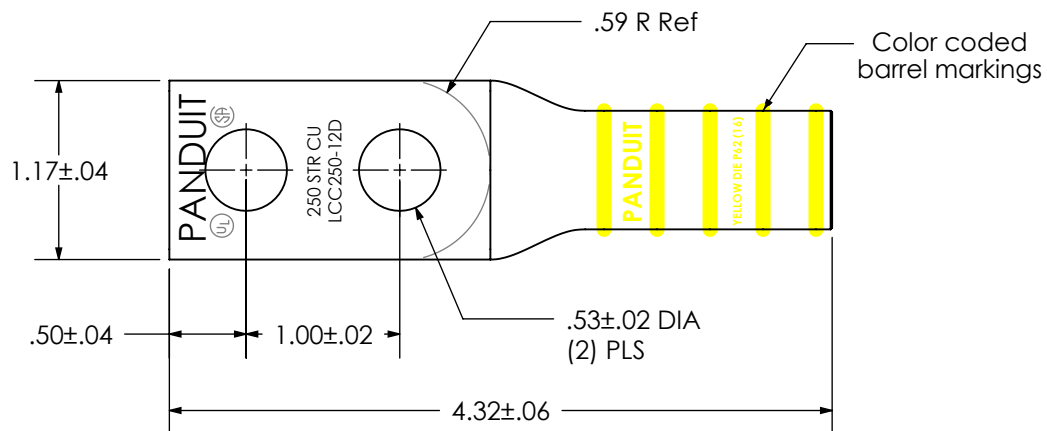

							PANDUIT CORP. TINLEY PARK, ILLINOIS	
							LCC250-12D-X	
							Copper Lug - Two-Hole, Long Barrel	
01	7/12	JHNU	JHNU	REMOVED NAVY NUMBER	N10883DI-LCC250-12D-CUST	RGB	RGB	
REV	DATE	BY	CHK	DESCRIPTION	ECN	-R	SUP	SCALE N/A
								DRAWING NO / CAD FILE LCC250-12D-CUST