

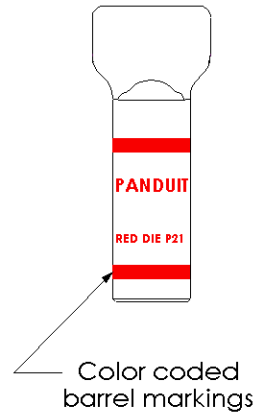


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

|                                                |                                                                                                                                                |
|------------------------------------------------|------------------------------------------------------------------------------------------------------------------------------------------------|
| Material                                       | High Conductivity Seamless Copper Tube                                                                                                         |
| Plating                                        | Electro-Tin                                                                                                                                    |
| Wire Size                                      | 8 AWG                                                                                                                                          |
| Wire Type                                      | Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric                                                               |
| Wire Strip Length                              | 3/4 in.                                                                                                                                        |
| Stud Size                                      | #10                                                                                                                                            |
| UL Listed Wire Connector                       | Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts. |
| UL Temperature Rating                          | 90° C                                                                                                                                          |
| C.S.A Certified Wire Connector                 | Yes                                                                                                                                            |
| Panduit Color Code on Barrel                   | RED                                                                                                                                            |
| Panduit Die Index No. on Barrel                | P21                                                                                                                                            |
| Alternate Industry Die Index No. ( ) on Barrel | N/A                                                                                                                                            |

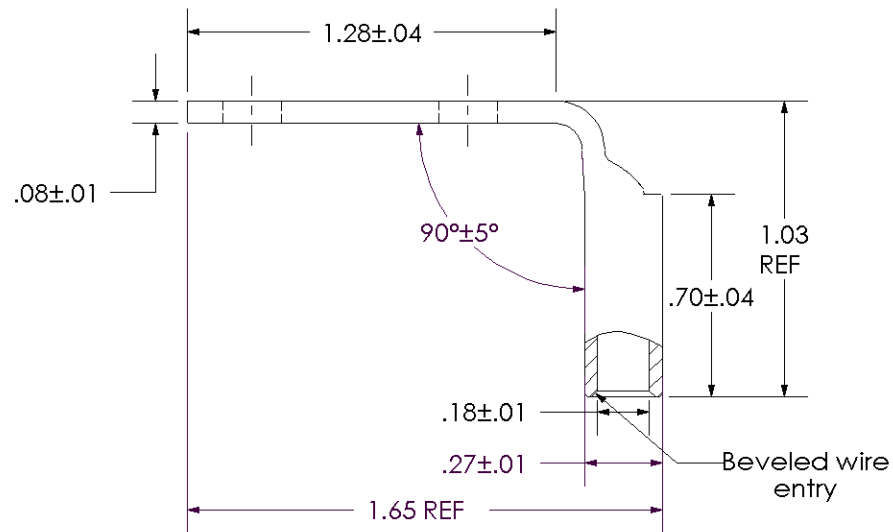

LISTED  
Wire Connector

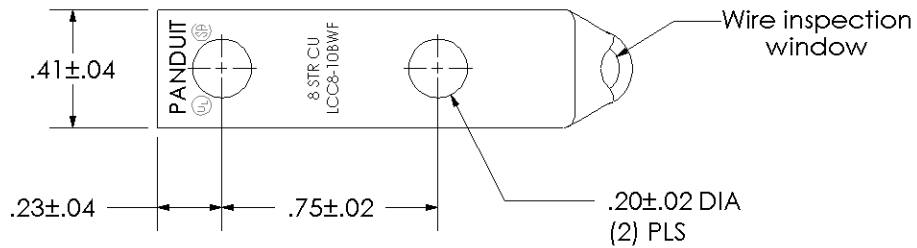

|     |      |     |     |             |
|-----|------|-----|-----|-------------|
| 00  | 9/02 | SAB | DRL | RELEASED    |
| REV | DATE | BY  | CHK | DESCRIPTION |

|                                                                                  |           |
|----------------------------------------------------------------------------------|-----------|
| PANDUIT CORP. TINLEY PARK, ILLINOIS                                              |           |
| LCC8-10BWF-L<br>Copper Lug - Two-Hole, Long Barrel with Window, 90° Angle Tongue |           |
| 10342                                                                            | SCALE N/A |
| DRAWING NO / CAD FILE LCC8-10BWF-CUST                                            |           |