
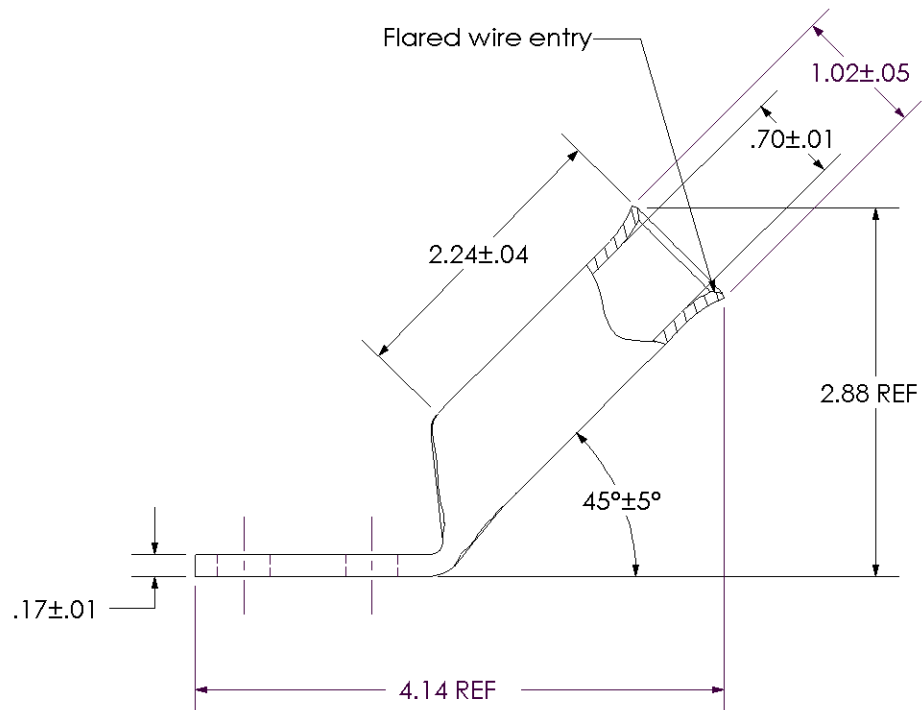


|                                                      |                                                                                                                                                            |
|------------------------------------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Material                                             | High Conductivity<br>Seamless Copper Tube                                                                                                                  |
| Plating                                              | Electro-Tin                                                                                                                                                |
| Wire Size & Type                                     | Stranded Copper Flex Cable;<br>262.2 kcmil (650/24) Diesel<br>Locomotive, 250 kcmil Class K<br>& Class M                                                   |
| Wire Strip Length                                    | 2-5/16 in.                                                                                                                                                 |
| Stud Size                                            | 3/8 in.                                                                                                                                                    |
| UL Listed Wire<br>Connector                          | Yes, for applications up to 35kv.<br>Consult cable manufacturer for<br>voltage stress relief instructions<br>with applications greater than<br>2000 volts. |
| UL Temperature<br>Rating                             | 90° C                                                                                                                                                      |
| C.S.A Certified<br>Wire Connector                    | Yes                                                                                                                                                        |
| Panduit Color Code<br>on Barrel                      | WHITE                                                                                                                                                      |
| Panduit Die Index No.<br>on Barrel                   | P66                                                                                                                                                        |
| Alternate Industry<br>Die Index No. ( )<br>on Barrel | (17)                                                                                                                                                       |

LISTED  
Wire Connector

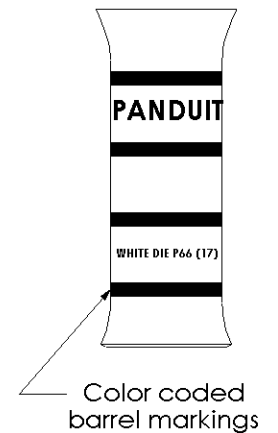

|     |      |     |     |             |       |                                                                                                                                  |                                            |
|-----|------|-----|-----|-------------|-------|----------------------------------------------------------------------------------------------------------------------------------|--------------------------------------------|
|     |      |     |     |             |       |  <b>PANDUIT CORP. TINLEY PARK, ILLINOIS</b> |                                            |
|     |      |     |     |             |       | LCCF250-38DH-X<br>Copper Lug - Two-Hole, Flared Barrel, 45° Angle Tongue                                                         |                                            |
| 00  | 8/02 | SAB | DRL | RELEASED    | 10337 |                                                                                                                                  |                                            |
| REV | DATE | BY  | CHK | DESCRIPTION | ECN   | SCALE<br>N/A                                                                                                                     | DRAWING NO / CAD FILE<br>LCCF250-38DH-CUST |