

Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	2/0 STR/FLEX
Wire Type	Stranded Copper: Class B & C Compact, Class G, H, I, K, M, Locomotive
Wire Strip Length	1-9/16 in.
Stud Size	3/8 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	BLACK
Panduit Die Index No. on Barrel	P45
Alternate Industry Die Index No. () on Barrel	(13)



Also stamped with:
2/0 STR/FLEX
LCBX2/0-38H


R.45 REF

PANDUIT


.96±.04

.39±.04

.41±.02 DIA

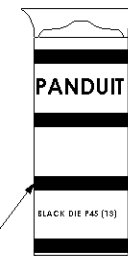

- Color coded barrel markings

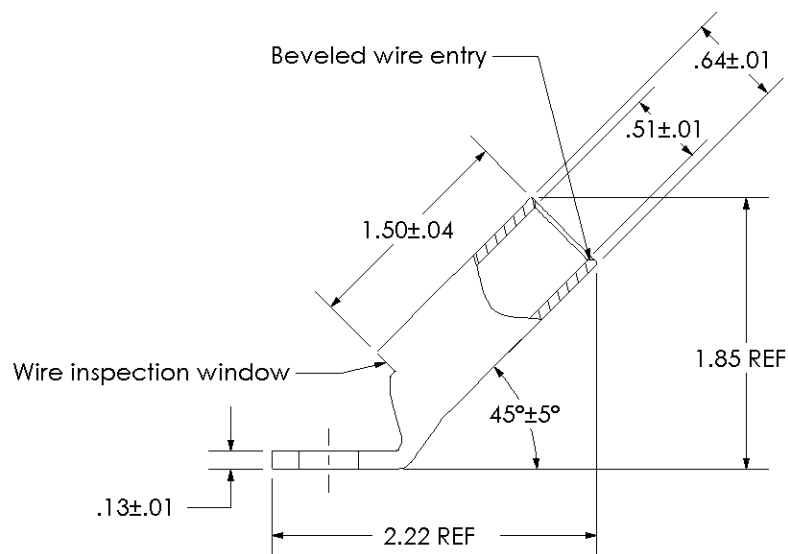

						 PANDUIT CORP. TINLEY PARK, ILLINOIS	
						LCBX2/0-38H-X Copper Lug - One-Hole, Long Flex Barrel, 45° Angle Tongue	
00	6/03	SAC	SAC	RELEASED	10850		
REV	DATE	BY	CHK	DESCRIPTION	ECN	SCALE N/A	DRAWING NO / CAD FILE LCBX2 0-38H-CUST