


Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	4/0 STR/FLEX
Wire Type	Stranded Copper: Class B & C, Compact, Class G, H, I, K, M, Locomotive
Wire Strip Length	2-5/16 in.
Stud Size	3/8 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	PURPLE
Panduit Die Index No. on Barrel	P54
Alternate Industry Die Index No. () on Barrel	(15)



Technical drawing of a 4/0 STR/FLEX LCCX4/0-38DH cable. The drawing shows a cross-section of the cable with the following dimensions and labels:

- Overall height: $1.19 \pm .04$
- Distance from the left edge to the center of the first hole: $.38 \pm .04$
- Distance between the centers of the two holes: $1.00 \pm .02$
- Radius of the fillet: $.44 \text{ R Ref}$
- Outer diameter of the cable: $.41 \pm .02 \text{ DIA (2) PLS}$
- Labels on the cable: PANDUIT, 4/0 STR/FLEX, LCCX4/0-38DH

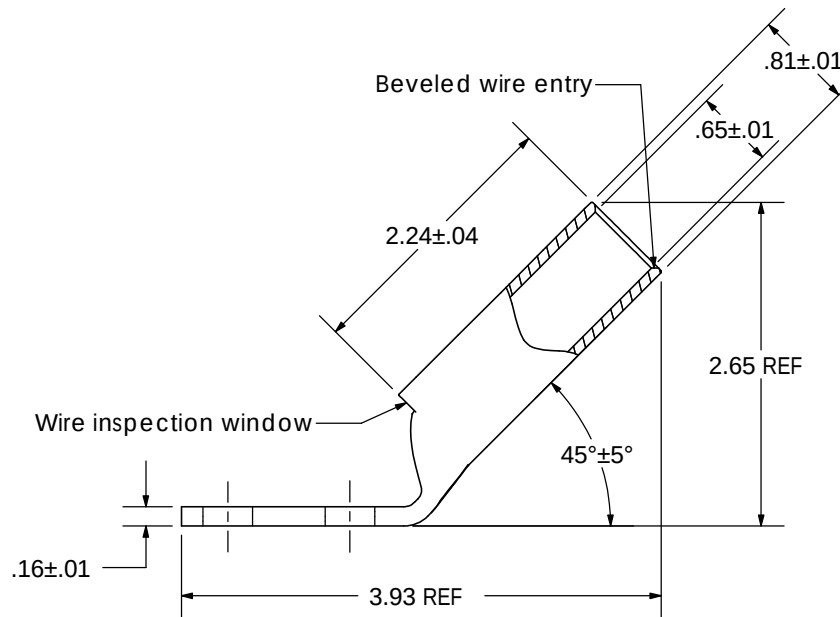

						 PANDUIT CORP. TINLEY PARK, ILLINOIS
						LCCX4/0-38DH-X
00	6/03	SAC	SAC	RELEASED	10850	Copper Lug - Two-Hole, Long Flex Barrel with Window, 45° Angle Tongue
REV	DATE	BY	CHK	DESCRIPTION	ECN	SCALE N/A DRAWING NO / CAD FILE LCCX4 0-38DH-CUST