

THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.



Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	2/0 STR/FLEX
Wire Type	Stranded Copper: Class B & C, Compact, Class G, H, I, K, M, Locomotive
Wire Strip Length	7/8 in.
Stud Size	3/8 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	BLACK
Panduit Die Index No. on Barrel	P45
Alternate Industry Die Index No. () on Barrel	(13)




CERTIFIED



LISTED
Wire Connector

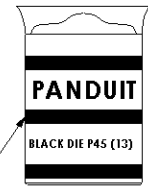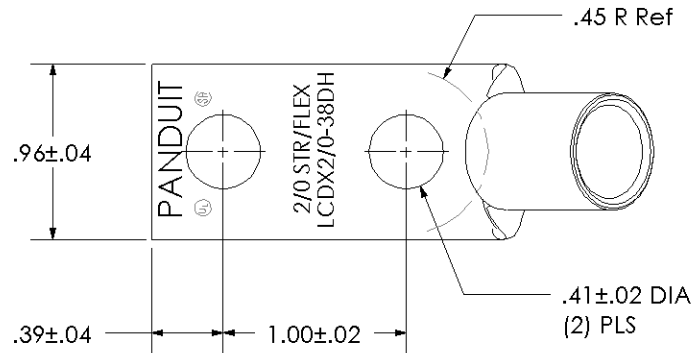

Color coded barrel markings

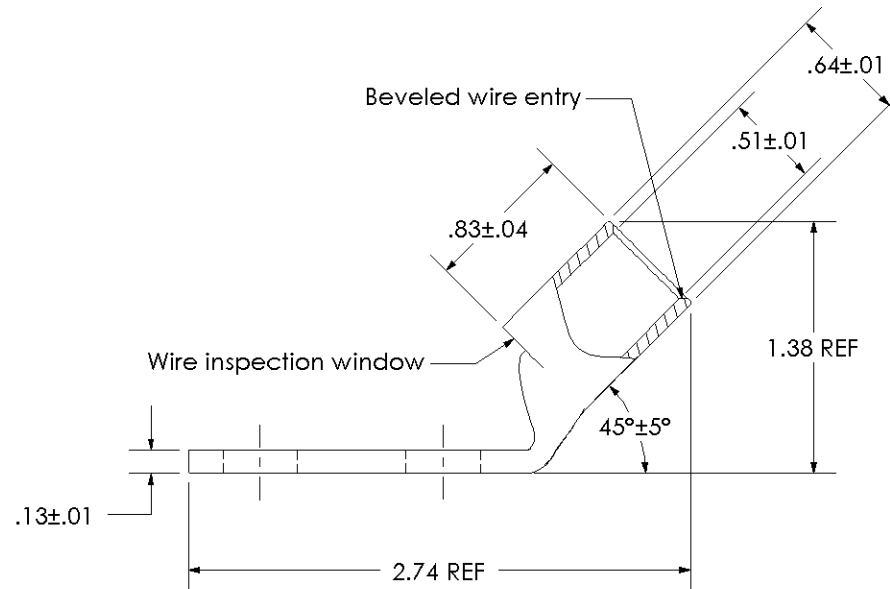

						PANDUIT CORP. TINLEY PARK, ILLINOIS	
						LCDX2/0-38DH-X Copper Lug - Two-Hole, Standard Flex Barrel, 45° Angle Tongue	
00	6/03	SAC	SAC	RELEASED	10850	SCALE N/A	DRAWING NO / CAD FILE
REV	DATE	BY	CHK	DESCRIPTION	ECN	LCDX2_0-38DH-CUST	