


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.


|                                                |                                                                                                                                                |
|------------------------------------------------|------------------------------------------------------------------------------------------------------------------------------------------------|
| Material                                       | High Conductivity Seamless Copper Tube                                                                                                         |
| Plating                                        | Electro-Tin                                                                                                                                    |
| Wire Size                                      | 3/0 AWG                                                                                                                                        |
| Wire Type                                      | Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric                                                               |
| Wire Strip Length                              | 1-9/16 in.                                                                                                                                     |
| Stud Size                                      | 3/8 in.                                                                                                                                        |
| UL Listed Wire Connector                       | Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts. |
| UL Temperature Rating                          | 90° C                                                                                                                                          |
| C.S.A Certified Wire Connector                 | Yes                                                                                                                                            |
| Panduit Color Code on Barrel                   | ORANGE                                                                                                                                         |
| Panduit Die Index No. on Barrel                | P50                                                                                                                                            |
| Alternate Industry Die Index No. ( ) on Barrel | (14)                                                                                                                                           |



LISTED  
Wire Connector

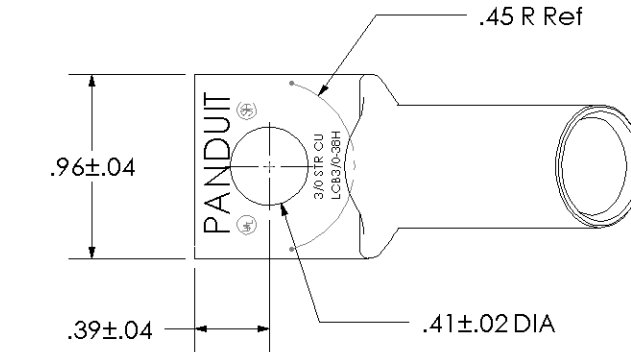

Color coded  
barrel markings

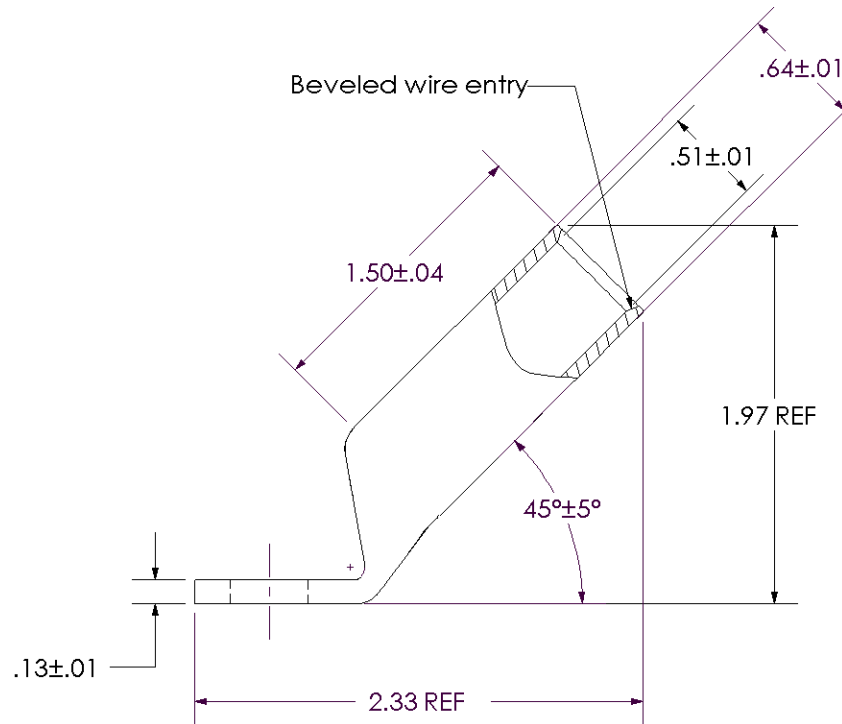

|     |       |     |     |
|-----|-------|-----|-----|
|     |       |     |     |
| 00  | 12/02 | SAB | DRL |
| REV | DATE  | BY  | CHK |

RELEASED  
DESCRIPTION

10328  
ECN

SCALE  
N/A

DRAWING NO / CAD FILE

LCB3\_0-38H-CUST

**PANDUIT**

**CORP. TINLEY PARK, ILLINOIS**

LCB3/0-38H-X

Copper Lug - One-Hole, Long Barrel, 45° Angle Tongue