

Search Results

Evaluate

- FAQ's

How to Buy

- Bill of Material

- Favorite Products List

- Locate Distributor


[Home](#) > [Products Overview](#) > [Search Results](#) >

Current refinements (click  to remove) [Search Tips](#)  Within Results

 **Text Search: 'F5B4-NM1Y'**

Your search criteria matched only one product, shown below

## F5B4-NM1Y

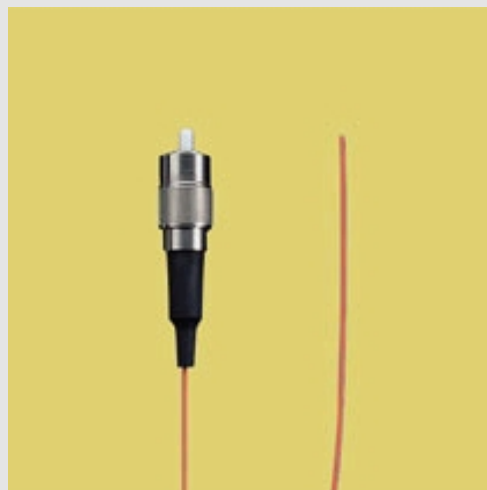

- Pass all TIA/EIA-568-B.3 performance requirements
- Insertion loss per connection: 0.10dB typical; 0.30dB maximum
- Factory terminated and 100% tested for insertion loss
- Insertion loss data recorded for every multimode patch cord
- Lifetime traceability of test data to a Q.C. number on each patch cord
- SC Duplex Patch Cords include SC Duplex Clips to maintain polarity
- Highest quality flame retardant fiber optic cable with tight -buffered coating on each optical fiber

Part Number	F5B4-NM1Y
RoHS Compliancy Status	Compliant
Note	F5B4-NM1Y replaces F5B4NM1
Part Description	FC to pigtail multimode simplex patch cord, 900m buffered fiber (one FC connector on one end and open on the other end) - 50/125µm.
Product Type	FC Patch Cords
Length (m)	1
Fiber Compatibility	50/125µm
Fiber Cable Size	900µm
Fiber Cable Type	Tight-buffered
Fiber Type	Multimode
Connector 1 Type	FC Connector
Connector 2 Type	Pigtail
End Configurations	FC to Pigtail
Fiber Count	1
Flammability Rating	Riser (OFNR)
Pricing Description	PC FC Pigtail Buffered 50 m 1m
Min. Order UOM	PC
Min. Order Qty.	1
BOM Qty. (# of Pkgs.)	<input type="text" value="0"/>
Add to Favorite Product List	

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'Favorite Product List' features.