

Search Results

Evaluate

- FAQ's

How to Buy

- Bill of Material

- Favorite Products List

- Locate Distributor


Home > Products Overview > Search Results >

Current refinements (click  to remove) Search Tips

 Text Search: 'MC75X75WH2'

Your search criteria matched only one product, shown below

## MC75X75WH2

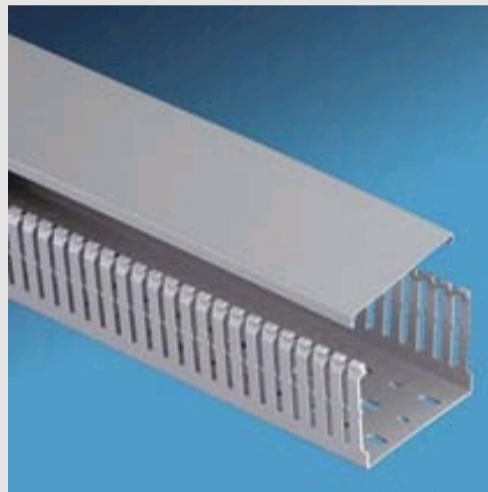

Choose from 22 sizes of *PANDUIT*® Type MC Wiring Duct from 25mm x 25mm up to 100mm x 100mm. Used for general purpose control panel wiring and to route and protect wiring in communication closets. Ideal for use with high density terminal blocks. The non-slip cover conceals all wiring and is easy to install. The duct and cover form a flush sidewall providing increased capacity and improved aesthetics.

### Specifications

- CE compliant and metric sizing for control panels intended for European applications
- Made of lead-free PVC
- Rated for continuous use temperatures up to 122°F (50°C)
- UL94 Flammability Rating V-0
- Conforms with NFPA 79-2002 section 14.3.1 requirement for flame retardant material
- Available in International Gray color and White color
- Provided with DIN 43 659 mounting holes
- Duct and cover packaged together in 2 meter lengths

### Features and Benefits

- Narrow finger design provides proper spacing for use with high density terminal blocks
- CE Marked eliminates custom delays, and rework on panels shipped to Europe
- *PANDUIT*® exclusive Rounded Edges will not cut installer's hands or wiring insulation
- Non-slip Cover will not slip when installed on duct base
- Flush Cover Design holds 10-12% more wires than traditional duct designs
- Double Scoreline saves installation time, and ultimately lowers installed cost
- Specially Formulated Lead Free material eliminates health concerns associated with PVC which contains lead
- Restricted Slot Design retains wire in slot for fast, easy wire installation or removal

Base and cover sold together.

|                              |   |
|------------------------------|---|
| Part Number                  | MC75X75WH2  |
| RoHS Compliancy Status       | Compliant   |
| Part Description             | Narrow finger, slotted metric wiring duct.        |
| Material                     | Lead-free PVC                                     |
| Color                        | White   |
| CSA Certified                | Yes   |
| CE Compliant                 | Yes   |
| CE Marking                   | Yes   |
| Duct Size W x H (In.)        | 2.94 x 2.85                                       |
| Duct Size W x H (mm)         | 74.7 x 72.4                                       |
| Mounting Method              | Standard Mounting Holes                           |
| Pricing Description          | Slotted Metric Duct, PVC, 75mm x 75mm x 2m, White |
| Slot Width (mm)              | 5.0   |
| Cover Part Number            | C75WH2  |
| Min. Order UOM               | MR  |
| Min. Order Qty.              | 10  |
| BOM Qty. (# of Pkgs.)        | <input type="text" value="0"/>                    |
| Add to Favorite Product List | <input type="button" value="e"/>                  |

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'Favorite Product List' features.