



Search Results

- Evaluate
- FAQ's
 - Product Bulletins
 - PDFTYPE H HN HS ..
 - Design a Solution

- Part Drawings
 - PDFTYPE HN Hing ..
 - PDFTYPE HN Hing ..
 - DWG-Type HN Hing ..
 - PDFTYPE HN Hing ..
 - PDFTYPE HN Hing ..
 - DWG-Type HN Hing ..
 - PDFTYPE HN Hing ..
 - PDFTYPE HN Hing ..
 - DWG-Type HN Hing ..
 - DXF-Type HN Hing ..
 - DWG-Type HN Hing ..
 - DXF-Type HN Hing ..
 - DXF-Type HN Hing ..
 - DXF-Type HN Hing ..
 - DXF-Type HN Hing ..
 - DWG-Type HN Hing ..
 - DXF-Type HN Hing ..
 - DWG-Type HN Hing ..
 - PDFTYPE HN Hing ..
 - PDFTYPE HN Hing ..

- How to Buy
- Bill of Material
 - Favorite Products List
 - Locate Distributor


Home > Products Overview > Search Results >

Current refinements (click to remove) Search Tips Within Results

Text Search: 'HN2X2WH6'

Your search criteria matched only one product, shown below

HN2X2WH6

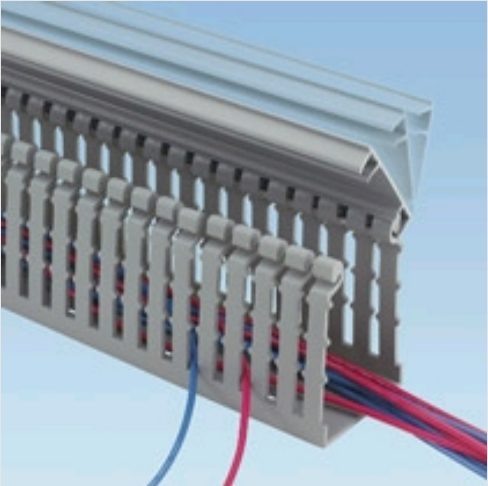

Type HN Wiring Duct is ideal for applications that require easy access in control panels and communication closets for frequent equipment modifications or repairs where moves, adds and changes are common. Due to the hinging feature, Hinged Cover Slotted Wall Wiring Duct reduces the time and hassle associated with removing and reinstalling traditional duct cover to perform maintenance or changes.

Specifications

- Narrow slot/finger design provides excellent wire management with smaller wire diameters and high -density components such as terminal blocks, input/output devices and other hardware
- Made of lead-free PVC
- Rated for continuous use temperature: 122°F (50°C)
- UL94 Flammability Rating V -0
- Conforms with NFPA 79 -2002 section 14.3.1 requirement for flame retardant material
- Available in Light Gray and White
- Provided with standard mounting holes

- Base and cover length is 6 feet

Features and Benefits

- Integrated hinged cover design allows easy access to wiring without hassle of removing and reinstaling cover
- Dual-sided hinge can open up to 100° from either sidewall of duct base for easy access to channel
- Cover retention flanges allows the cover to open and close easily
- Double scoreline allows fingers and complete sidewall removal
- Cover removal rib makes cover easy to open from either side
- Three level restricted slot design retains wire in slot for fast, easy wire installation or removal

Base and cover sold separately.

Part Number	HN2X2WH6
RoHS Compliancy Status	Compliant
Part Description	Narrow finger hinged cover wiring duct.
Material	Lead-free PVC
Color	White
CSA Certified	Yes
UL Recognized (File No. E147128)	Yes
Length (ft.)	6
Duct Size W x H (In.)	2.17 x 1.98
Duct Size W x H (mm)	55.1 x 50.3
Mounting Method	Standard mounting holes
Pricing Description	Hinged Duct, Narrow Finger
Slot Width (In.)	.20
Slot Width (mm)	5.0
Cover Part Number	HC2WH6
Min. Order UOM	FT
Min. Order Qty.	6
BOM Qty. (# of Pkgs.)	0
Add to Favorite Product List	

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'Favorite Product List' features.