

Search Results

Evaluate

- FAQ's
- Press Releases
- Stainless St..
- Product Bulletins
- PDFStainless St..

Design a Solution

- Part Drawings
- PDFMLT, Heavy S..

How to Buy

- Bill of Material
- Favorite Products List
- Locate Distributor


Home > Products Overview > Search Results >

Current refinements (click  to remove) Search Tips

 Text Search: 'MLTFC2HLP316YL'

Your search criteria matched only one product, shown below

MLTFC2HLP316YL

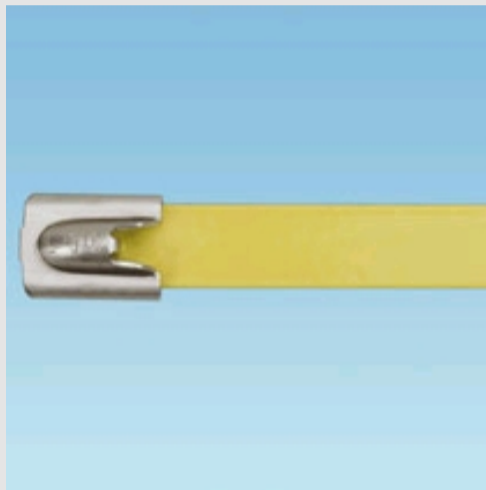

- Polyester coating available in six color options provides visual indication for easy identification in color-coding applications (heavy cross section only)
 - Self-locking head design speeds installation and locks into place at any length along the tie body
 - Polyester coating provides additional edge protection and prevents corrosion between dissimilar metals
 - AISI 316 stainless steel for the most corrosive environments
 - Available in standard, heavy, extra-heavy and super-heavy cross sections
 - UV resistant, low smoke, halogen -free material
 - Temperature tolerance -40°F (-40°C) to 302°F (150°C)
- Part thickness is base material less coating.

| | |
|-------------------------------------|---|
| ▪ Part Number | MLTFC2HLP316YL |
| ▪ RoHS Compliancy Status | Compliant |
| ▪ Part Description | Polyester coated stainless steel tie, AISI 316, heavy, 7.9" length. |
| ▪ Product Type | Stainless Steel Cable Tie |
| ▪ Material | Stainless Steel Type 316 (V4A) |
| ▪ Color | Yellow |
| ▪ Length (In.) | 7.9 |
| ▪ Length (mm) | 201 |
| ▪ Width (In.) | 0.31 |
| ▪ Width (mm) | 7.9 |
| ▪ Max. Bundle Diameter (In.) | 2.0 |
| ▪ Max. Bundle Diameter (mm) | 51 |
| ▪ Min. Bundle Diameter (In.) | 0.50 |
| ▪ Min. Bundle Diameter (mm) | 12.7 |
| ▪ Min. Loop Tensile Strength (Lbs.) | 250 |
| ▪ Min. Loop Tensile Strength (N) | 1112 |
| ▪ Pricing Description | MLT Tie, 316 SS, Fully Coated, Heavy, 7.9" (201mm), .010" (.25mm) thk, Yellow |
| ▪ Temperature Range | -40°C– 150°C |
| ▪ Thickness (In.) | 0.010 |
| ▪ Thickness (mm) | 0.25 |
| ▪ Tool | GS4MT, ST2MT, HTMT, PPTMT, PBTMT |
| ▪ Min. Order UOM | PC |
| ▪ Min. Order Qty. | 50 |
| ▪ BOM Qty. (# of Pkgs.) | <input type="text" value="0"/> |
| ▪ Add to Favorite Product List |  |

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'Favorite Product List' features.