



Search Results

- Evaluate
- FAQ's
- How to Buy
- Bill of Material
 - Favorite Products List
 - Locate Distributor


[Home](#) > [Products Overview](#) > [Search Results](#) >

Current refinements (click to remove) [Search Tips](#)

Text Search: 'TGRAIG'

Your search criteria matched only one product, shown below

TGRAIG

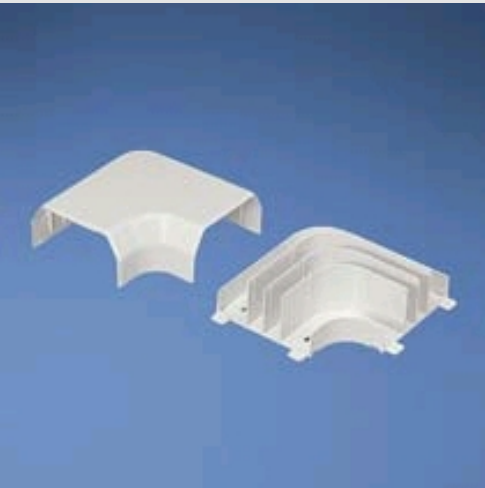

- TG-70 fittings are designed to exceed the TIA/EIA-568-B and 569-B required minimum bend radius for high performance copper and fiber optic cabling systems
- All AW (Arctic White) and two and three meter products are only available outside of North America as a standard item. Contact customer service for minimum order quantities, stock and other color availability.***

	Part Number	TGRAIG
	RoHS Compliancy Status	Compliant
	Part Description	Right angle fitting. Used to join sections of TG raceway at 90° flat junctions.
	Product Type	Power Rated Fittings
	Color	International Gray
	CSA 22.2 No.6293	Yes
	UL5A Listed	Yes
	CE Compliant	Yes
	CE Marking	Yes
	Pricing Description	TG-70 Right Angle Fitting
	Product Size	70
	Min. Order UOM	PC
	Min. Order Qty.	1
	BOM Qty. (# of Pkgs.)	0
	Add to Favorite Product List	

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'Favorite Product List' features.