

**Search Results**

Evaluate

- Brochures
- PDFWyr-Grid Ove..
- FAQ's

Design a Solution


- Part Drawings
- PDF18in. Wyr-Gr ..
- Specification Sheets
- PDFWyr-Grid Ove..

How to Buy

- Bill of Material
- Favorite Products List
- Locate Distributor


Home > Products Overview > Search Results >

Current refinements (click  to remove) Search Tips


 Text Search: 'WG18BL10'

Your search criteria matched only one product, shown below

**WG18BL10**

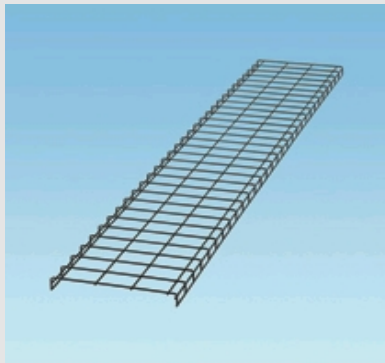

- Pathways are provided in four widths: 12" (305mm), 18" (457mm), 24" (610mm) and 30" (762mm)
- Standard finish is black powder coat
- Non-integral sidewalls minimize specification requirements

Part Number	WG18BL10
RoHS Compliancy Status	Compliant
Part Description	18" wide x 10' long pathway section used to carry cables horizontally throughout the system. Snap-on sidewalls attach for job specific height requirements. Uses splice connector WGSP1218BL to connect straight sections and intersection splice WGINTSPLBI to connect pathways at an intersection.
Color	Black
Length (ft.)	10
Pricing Description	Wyr-Grid Pathway, 18" W x 10' L
Min. Order UOM	FT
Min. Order Qty.	10
BOM Qty. (# of Pkgs.)	<input type="text" value="0"/>
Add to Favorite Product List	

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'Favorite Product List' features.