
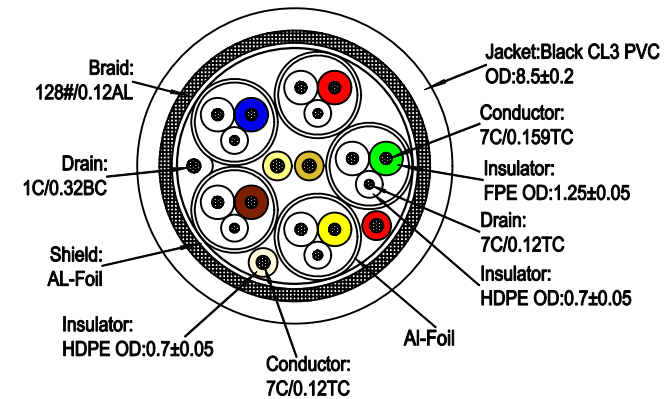


This label to be placed on the outside of Quest cable bags

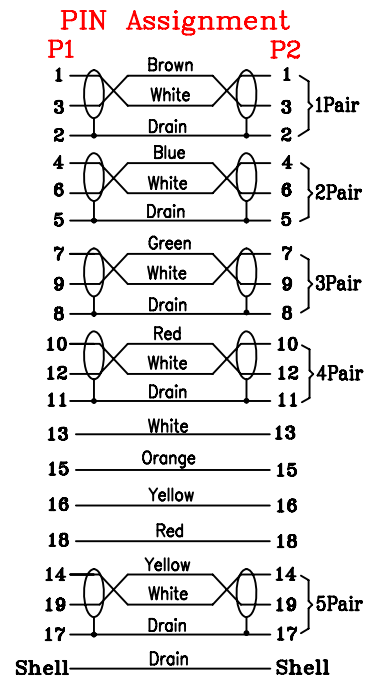

CABLE SPECIFICATION:
26AWG 2.0V HDMI Cable/OD:8.5mm/Black CL3 PVC
{[(7C/0.159TC+FPE OD:1.25mm)*1P+7C/0.12TC
+HDPE OD:0.7mm+AL]*5P
+(7C/0.12TC+HDPE OD:0.7mm)*4C
+AL+1C/0.32BC+128#/0.12AL+CL3 PVC OD:8.5mm}

CLIENT NO:	HDI-1420	HDI-1425	HDI-1430	HDI-1440	HDI-1450
LENGTH (L)	20FT±60mm	25FT±70mm	30FT±100mm	40FT±120mm	50FT±150mm

NOTES:

- Test Condition:
 - 100% OPEN & SHORT TEST;
 - Insulation Resistance: DC300V 5MΩ(Min) ;
 - Conductor Resistance: 5Ω/Max.
- The product is ROHS compliant.
- HDTV-DVD TEST:1080P&3D&4K*2K

				DESCRIPTION	HDMI (M-M) CABLE W/ENET,4K2K,CL3, 26AWG	SCALE	FIT	UNITS: MM	3RD ANGLE
				MODEL NO,	HDI-14xx - 26AWG	△			
APPROVED	CHECKED	DRAWING	DESIGNED	DRAWING NO,		△			
		ELLA	ELLA	FINISHING		△	2016/04/12		A1
				MATERIAL		SYM	DATE		REVISION