



1800 ± 20mm
1800 ± 20mm

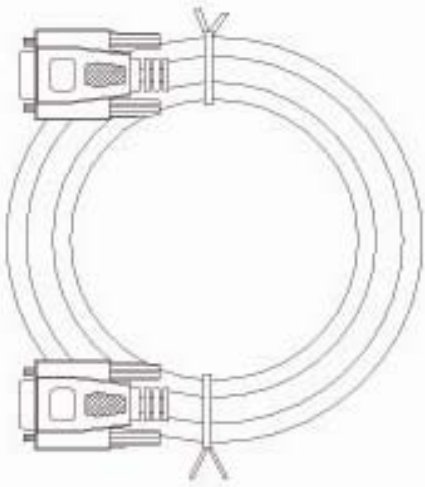

1. RD	1. RD
2. GR	2. GR
3. BL	3. BL
4. BN	4. BN
5. BK	5. BK
6. PK	6. PK
7. GY	7. GY
8. LP	8. LP
9. LB	9. LB
10. OG	10. OG
11. WH	11. WH
12. YW	12. YW
13. LS	13. LS
14. RD	14. RD
15. DG	15. DG
10, shell I	10, shell II

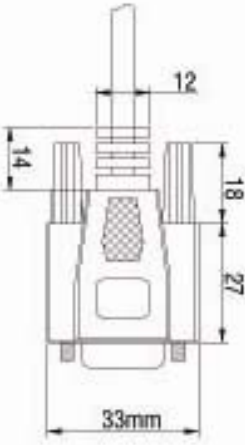

NCC-9906