
 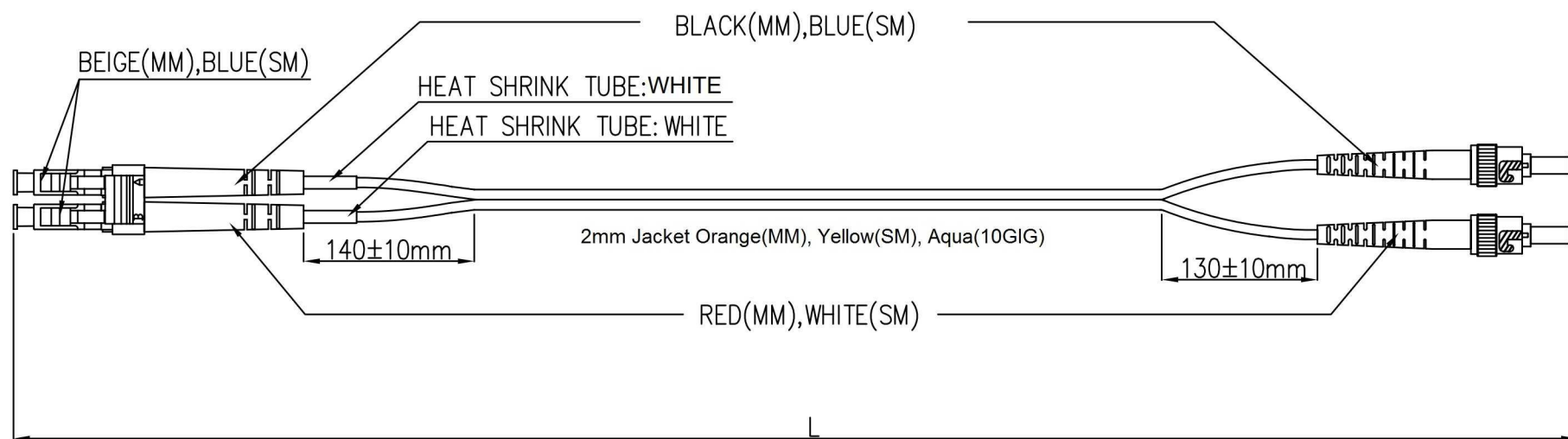




SPECIFICATIONS:

Type	Multi-Mode	Single Mode	LENGTH (L)	TOLERANCE
Insertion Loss	≤0.5dB	≤0.2dB	< 1M	+50mm/-0
Return Loss	≥20dB	≥55dB	≥1M <10M	+100mm/-0
Test Wavelength	850nm	1310nm	≥10M <30M	+150mm/-0
			≥30M	+1%/-0

LENGTH TOLERANCE:

		Designed By		DESC.		DX LC—ST JUMPER	
Tolerances unless otherwise specified:		Checked By					
		Approved By		DRG. No.			
Scale						Quest Technology Int'l, Inc. 11200 NW 138th St., Medley, FL 33178 Tel: 305-513-8883 Fax: 305-513-9675 www.QuestTechnologyIntl.com	
Version		1.0					