

CAT6A UTP PATCH CORD


QUEST CABLING SOLUTIONS CAT6A 550MHZ UTP 60°C ISO/IEC 11801& EN50288 & ANSI/TIA-568C.2
ETL/3P VERIFIED - 24AWGX4P PATCH TYPE CMR ROHS

JACKET:PVC OD6.0±0.1
Insulation:HDPE 1.02±0.02


NPC-3XXX
LENGTH
COLOR

COLOR(X)	
BLUE	2
GREY	9

- W/OR 1 OR 2
- W/GR 3 GR 6
- BL 4 W/BL 5
- W/BR 7 BR 8

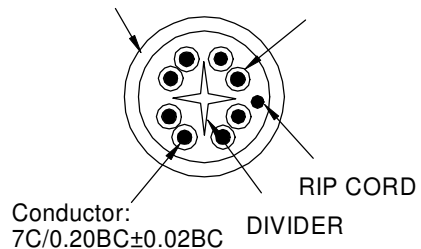

Length: 3', 7', 10', 15', 25'

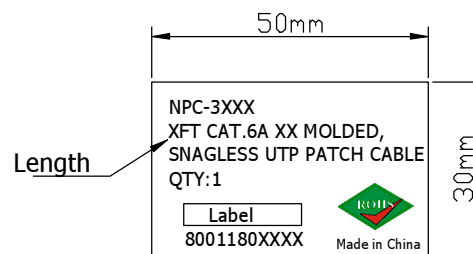

9			
8			
7			
6			
5			
4			
3	60P PVC MOLDED	12	g
2	8P8C MALE GOLD PLATED PIN 50U"	2	pcs
1	CABLE:(7C/0.20BC±0.02BC+HDPE1.02)*4P+RIP OD:6.0±0.1MM	1	pcs
NO	Description	Q,TY	Unit

				DESCRIPTION	CAT6A UTP PATCH CORD	SCALE	FIT	UNITS:MM	3RD ANGLE
Quest Technology Int'l, Inc. 11200 NW 138th St, Mckley, FL 33178 Tel: 800-810-8888 Fax: 305-810-8878 www.QuestTechnologyIntl.com				MODEL NO	NPC-3XXX	△			
APPROVED	CHECKED	DRAWING	DESIGNED	DRAWING NO	URT6A-M45-XX-XX	△			
Wxp	Wxp	David Feng	David Feng	FINISHING		△	2014.05.09		A1
				MATERIAL		SYM	DATE		REVISION