


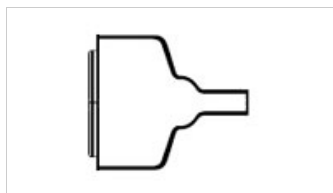

What can we help you find?

[Products](#) | [Industries](#) | [Resources](#) | [About TE](#) | [My Account](#) | [Innovation](#) | [Support Center](#)

214A342-25-0 Product Details

[Share](#) | [Print](#) | [Email](#)


Active

Molded Parts

214A342-25-0

214A342-25-0

TE Internal Number: 879436-000

Product Highlights [View All](#)

- DEF Std 59-97 Issue 3 Type DE, MIS-34867, VG95343 Parts 6, 7, 8, & 9
- Molded Part Type = D Subminiature Boot
- Operating Temperature = -75 - 150 °C
- Adhesive Options = S1125 Separate Adhesive
- 180°

[Pricing & Availability](#)[Request Sample](#)[Add to My Part List](#)[Buy Product through Distributor](#)[Documents](#)[Features](#)[Compliance](#)**Please Note:**

Use the Product Drawing for all design activity

Product Type Features

Molded Part Type	D Subminiature Boot
Angle	180°
Adhesive Description	Adhesive Purchased Separately
Size	42
Family Name	214A3

Mechanical Attachment

Adhesive Pre-Coating	Without
----------------------	---------

Dimensions

Cable Diameter Range (mm [in])	8.60 - 17.30 [0.339 - 0.681]
Connector Length (mm [in])	58.00 - 58.70 [2.283 - 2.311]
Connector Width (mm [in])	10.70 [0.421]

Body Features

Material	Fluid Resistant Modified Elastomer
----------	------------------------------------

Configuration Features

Material Code	25
---------------	----

Industry Standards

Government/Industry Qualification	No
Approved Standards	DEF Std 59-97 Issue 3 Type DE, MIS-34867, VG95343 Parts 6, 7, 8, & 9
RoHS/ELV Compliance	RoHS compliant, ELV compliant
Lead Free Solder Processes	Not relevant for lead free process
RoHS/ELV Compliance History	Always was RoHS compliant

Environmental

Operating Temperature (°C)	-75 - +150
----------------------------	------------

Operation/Application

Application	General Purpose, Military
-------------	---------------------------

Purchasing Information

Housing Features

Material Systems Code 25

Adhesive Code S1125

Other

Adhesive Options S1125 Separate Adhesive

Brand Raychem

Comment Contact Raychem for additional adhesive and/or cut off boot length information

Related Products

Not quite the product you're looking for?

[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)
- [Global Accessibility Statement](#)

Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

Keep Me Informed

