


## 44A1131-22-0/2/9-9-US Product Details

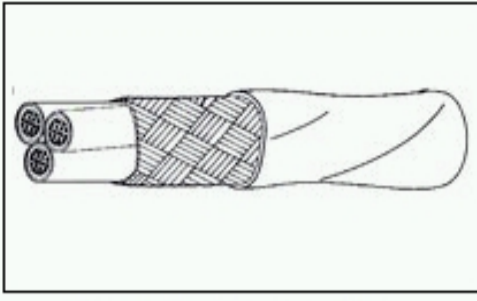

**44A1131-22-0/2/9-9-US**

TE Part Number: 382309-022

Active

Add to Part List

### Spec 44, Spec 55 and Spec RCW Wire and Cable

Not EU RoHS or ELV Compliant

#### Product Highlights:

- Wire Source = United States
- Cable Type = Spec 44
- Cable Style = Jacketed, Round-Braid Shielded
- Wire Size (AWG/CM) = 22 AWG
- Voltage Rating = 600 VAC

[View all Features](#) | [Find Similar Products](#)

#### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

NEW!

### Documentation & Additional Information

#### Product Drawings:

- [CABLE, RADIATION-CROSSLINKED, POLYALKENE-INSULATED, ...](#) (PDF, English)
- [THREE CONDUCTOR CABLE, RADIATION-CROSSLINKED, POLYAL...](#) (PDF, English)

#### Catalog Pages/Data Sheets:

- [Wire and Cable, Harnessing and Protection Products](#) (PDF, English)

#### Product Specifications:

- None Available

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files:

- None Available

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- [Cable Style](#) = Jacketed, Round-Braid Shielded
- Number of Conductors = Twisted Triple

#### Electrical Characteristics:

- Voltage Rating (VAC) = 600

#### Body Related Features:

- Wire Size (AWG/CM) = 22 AWG
- Cable Jacket Color = White
- Conductor Type = Tin-Plated Copper
- Wire Color = Black, Red, White
- Outside Diameter (mm [in]) = 3.56 [0.140]
- Wire Diameter (mm [in]) = 1.19 [0.047]
- Conductor O.D. (mm [in]) = 0.79 [0.031]

#### Configuration Related Features:

- [Cable Type](#) = Spec 44

#### Industry Standards:

- Government/Industry Qualification = No
- [RoHS/ELV Compliance](#) = Not ELV/RoHS compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process

#### Conditions for Usage:

- Temperature Range (°C) = -65 - +150

#### Operation/Application:

- Application = General Purpose - Lightweight

#### Packaging Related Features:

- Wire Source = United States
- Wire Size - Details = 22 AWG 0.38 mm<sup>2</sup>, 0.00059 in<sup>2</sup>, 19 x 34 AWG
- Shield (Screen) Diameter (mm [in]) = 3.15 [0.124]

#### Other:

- Brand = Raychem