


**Product Details for 44AM1111 - 14 - 9 - 9CS2275**

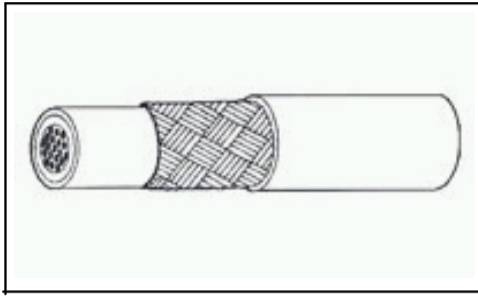

**Spec 44 and Spec 55 Wire and Cable**

[Not ELV or RoHS Compliant](#)

**Product Highlights:**

- ? Wire Source = United States
- ? Cable Type = Spec 44
- ? Cable Style = Jacketed, Round -Braid Shielded
- ? Wire Size (AWG/CM) = 14 AWG
- ? Voltage Rating = 600 VAC

[View all Features](#)

**44AM1111 - 14 - 9 - 9CS2275**

Tyco Part Number: 739053 - 000

[Active](#)

**Quick Links**

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

**Documentation & Additional Information**

**Product Drawings:**

- ? [Customer Drawing](#) (PDF, English)

**Catalog Pages/Data Sheets:**

- ? [Wire and Cable, Harnessing and Protection Products](#) (PDF, English)

**Product Specifications:**

- ? None Available

**Application Specifications:**

- ? None Available

**Instruction Sheets:**

- ? None Available

**CAD Files:**

- ? None Available

**Additional Information:**

- ? [Product Line Information](#)

**Related Products:**

- ? [Tooling](#)

[List all Documents](#)

**Product Features** (Please use the Product Drawing for all design activity)

**Product Type Features:**

- ? [Cable Style](#) = Jacketed, Round -Braid Shielded
- ? Number of Conductors = 1

**Electrical Characteristics:**

- ? Voltage Rating (VAC) = 600

**Body Related Features:**

- ? Wire Size (AWG/CM) = 14 AWG
- ? Cable Jacket Color = White
- ? Conductor Type = Tin -Coated Copper
- ? Wire Color = White
- ? Outside Diameter (mm [in]) = 3.23 [0.127]
- ? Wire Diameter (mm [in]) = 2.26 [0.089]
- ? Conductor O.D. (mm [in]) = 1.79 [0.070]

**Configuration Related Features:**

- ? [Cable Type](#) = Spec 44

**Industry Standards:**

- ? Government/Industry Qualification = No
- ? [RoHS/ELV Compliance](#) = Not ELV/RoHS compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process

**Conditions for Usage:**

- ? Temperature Range (°C) = -65 - +150

**Operation/Application:**

- ? Application = General Purpose - Lightweight

**Packaging Related Features:**

- ? Wire Source = United States
- ? Wire Size - Details = 14 AWG 1.94 mm<sup>2</sup>, 0.003 in<sup>2</sup>, 19 x 27 AWG
- ? Shield (Screen) Diameter (mm [in]) = 2.82 [0.111]

**Other:**

- ? Brand = Raychem