


202G221-780-02-0 Product Details

 [Share](#)
 [Print](#)
 [Email](#)

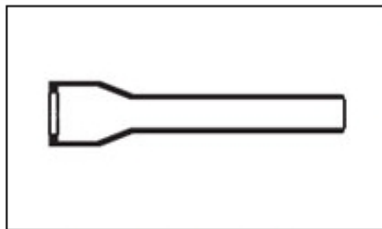

202G221-780-02-0

TE Internal Number: CC2410-000

 [Active](#)

Molded Parts

 [Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Molded Part Type = Molded Boot
- Family Name = 202G2
- Straight
- Hazardous Environment Application, Military Application
- Entry Size, Braided or Magneform Adapter = 7, 8, 9

[View all Features](#)

 [Add to My Part List](#)
 [Request Sample](#)
 [Find Similar Products](#)
 [Buy Product](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [Boot, Straight, with Lip](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Molded Part Type](#) = Molded Boot
- Size = 21
- Color = Black
- Material = NBCCS

Electrical Characteristics:

- Angle = Straight

Body Features:

- Cable Diameter Range (mm [in]) = 8.40 - 18.50 [0.331 - 0.728]

Contact Features:

- [Family Name](#) = 202G2
- Entry Size, Braided or Magneform Adapter = 7, 8, 9

Housing Features:

- Entry Size, Tinel-Lock Adapter = 5, 6, 7, 8
- Entry Size - Solid or Fixed Adapter = 4
- Entry Size - Spin Coupling Adapter = 6 - 7
- Adapter Entry Size Outside Diameter (Min-Max) (mm [in]) = 15.70 - 21.00 [0.618 - 0.827]
- [Material Systems Code](#) = 300
- Adhesive Pre-Coating = Without

Configuration Features:

- Material Code = 55

Industry Standards:

- Government/Industry Qualification = No
- Approved Standards = AR-7071, Raychem RT-700
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Environmental:

- Operating Temperature (°C) = -65 - +200

Operation/Application:

- Application = Hazardous Environment, Military

Other:

- Brand = Raychem
- Comment = Contact Raychem for additional adhesive and/or cut off boot length information; Boot with Lip

Corporate Information

[Who We Are](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)

Quick Links

[Check Distributor Inventory](#)
[Cross Reference](#)
[Find Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support

[Email or Chat With Us](#)
[Find a Phone Number](#)
[Search Knowledge Base](#)
[Manage your Account](#)

Keep Me Informed

Receive TE News, Events & Technology Updates

Enter your email address

