


44A1141-26-0/2/6/9-9 Product Details

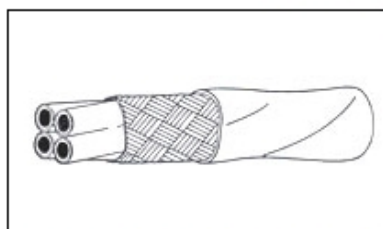

44A1141-26-0/2/6/9-9

TE Internal Number: 3825903001

[Active](#)

Spec 44, Spec 55 and Spec RCW Wire and Cable

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Cable Type = Spec 44
- Wire Source = United Kingdom
- Cable Style = Jacketed, Round-Braid Shielded
- Wire Size (AWG/CM) = 26 AWG
- Voltage Rating = 600 VAC

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

Documentation & Additional Information

Product Drawings:

- None Available

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Cable Type](#) = Spec 44
- [Cable Style](#) = Jacketed, Round-Braid Shielded
- Number of Conductors = Twisted Quad

Electrical Characteristics:

- Voltage Rating (VAC) = 600

Body Related Features:

- Wire Size (AWG/CM) = 26 AWG
- Cable Jacket Color = White
- Conductor Type = Tin-Plated Copper
- Wire Color = Black, Blue, Red, White
- Outside Diameter (mm [in]) = 3.12 [0.123]
- Wire Diameter (mm [in]) = 0.86 [0.034]
- Conductor O.D. (mm [in]) = 0.50 [0.020]

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Conditions for Usage:

- Temperature Range (°C) = -65 - +150

Operation/Application:

- Application = General Purpose - Lightweight

Packaging Related Features:

- Wire Source = United Kingdom
- Wire Size - Details = 26 AWG 0.15 mm², 0.00024 in², 19 x 38 AWG
- Shield (Screen) Diameter (mm [in]) = 2.72 [0.107]

Other:

- Brand = Raychem

BOOKMARK

Corporate Information

- [Who We Are](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)

Quick Links

- [Check Distributor Inventory](#)
- [Cross Reference](#)
- [Find Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat with Us](#)
- [Find a Phone Number](#)
- [Search Knowledge Base](#)
- [Manage Your Account](#)