


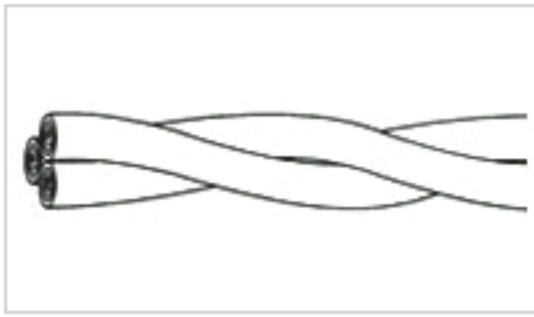

44A0131-16-0/2/9-MX Product Details

[Share](#) | [Print](#) | [Email](#)


✔ Active

Spec 44, Spec 55 and Spec RCW Wire and Cable

44A0131-16-0/2/9

44A0131-16-0/2/9-MX ✔

TE Internal Number: 383094-000

Product Highlights [View All](#)

- Cable Type = Spec 44
- Wire Source = United States
- Cable Style = Primary
- Wire Size (AWG/CM) = 16 AWG
- Voltage Rating = 600 VAC

- [Pricing & Availability](#)
- [Request Sample](#)
- [Add to My Part List](#)
- [Buy Product through Distributor](#)

Feedback

[Documents](#) | [Features](#) | [Compliance](#)

Please Note:

Use the Product Drawing for all design activity

Product Type Features		Industry Standards	
Cable Type [?]	Spec 44	Government/Industry Qualification	No
Cable Style [?]	Primary	RoHS/ELV Compliance [?]	RoHS compliant, ELV compliant
Electrical Characteristics		Lead Free Solder Processes [?]	Not relevant for lead free process
Voltage Rating (VAC)	600	RoHS/ELV Compliance History	Always was RoHS compliant
Dimensions		Conditions for Usage	
Conductor Outer Diameter (mm [in])	1.42 [0.056]	Temperature Range (°C)	-65 - +150
Body Features		Wire Size - Details	16 AWG 1.23 mm ² , 0.002 in ² , 19 x 29 AWG
Wire Size (AWG/CM)	16 AWG	Operation/Application	
Conductor Type	Tin-Coated Copper	Application	General Purpose - Light Weight
Wire Color	Black, Blue, Red	Packaging Features	
Nominal Outside Diameter (mm [in])	3.96 [0.156]	Wire Source	United States
Wire Diameter (mm [in])	1.83 [0.072]	Other	
Configuration Features		Brand	Raychem
Number of Conductors	Twisted Triple	Node Classification	Multicore Cable

Related Products

Not quite the product you're looking for?
[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)