



Search by part # or keyword

[Products](#)

[Industries & Solutions](#)

[Resources](#)

[TE Store](#)

[Sign In](#)



[Connectors](#) > [D-Shaped Connectors](#) > [D-Sub Accessories](#) > [D-Sub Connector Boots](#)

214A032-25/225-0

214A032-25/225-0



Raychem

TE Internal #: **587829-000**

TE Internal Description: **214A032-25/225-0**

Alias #: **9-1194651-3**

Angle : **Straight**

Adhesive Pre-Coating : **With**

Adhesive Description : **Unicure Pre-Coated**

Epoxy Adhesive

Sealable : **Yes**

Operating Temperature Range (°F): **-103 – 302**

[Similar Products](#)

[Compatible Parts & Tooling](#)

We are here to help!

Get in touch with our product experts.



[CHAT WITH US](#)



[EMAIL US](#)



[CALL US](#)

Feedback

Documents

Features

Product Compliance

Product Drawings

- 214A032-25/225-0
[214A032-25/225-0](#) English
- 214A032-25/225-0
[214A032-25/225-0](#) English

Datasheets & Catalog Pages

- 1654025_Sec4_-25
[ENG_CS_1654025_Sec4_-25_0313.pdf](#) English

Product Specifications

- Product Specification
[ENG_SS_RW-2070_2.pdf](#) English

Product Environmental Compliance

- Safety Datasheet
[ENG_MSDS_RAY3111-EC-ENG_2018-08-31.pdf](#) English
- [FRE_MSDS_RAY3111-EC-FRE_2018-08-28.pdf](#) French
- Safety Datasheet
[GER_MSDS_RAY3111-EC-GER_2018-08-28.pdf](#) German
- Safety Datasheet
[ITA_MSDS_RAY3111-EC-ITA_2018-08-28.pdf](#) Italian
- Safety Datasheet
[SPA_MSDS_RAY3111-EC-SPA_2018-08-28.pdf](#) Spanish
- Safety Datasheet

[SWE_MSDS_RAY3111-EC-SWE_2018-08-28.pdf](#)

Swedish

Safety Datasheet

[DUT_MSDS_RAY3111-EC-DUT_2018-08-28.pdf](#)

Dutch

Safety Datasheet

[DAN_MSDS_RAY3111-EC-DAN_2018-08-28.pdf](#)

Danish

Safety Datasheet

[ENG_MSDS_SDS0190-EC-ENG_2014-04-10.pdf](#)

English

Safety Datasheet

[FRE_MSDS_SDS0190-EC-FRE_2014-04-10.pdf](#)

French

Safety Datasheet

[GER_MSDS_SDS0190-EC-GER_2014-04-10.pdf](#)

German

Safety Datasheet

[ITA_MSDS_SDS0190-EC-ITA_2014-04-10.pdf](#)

Italian

Safety Datasheet

[NOR_MSDS_SDS0190-EC-NOR_2014-04-10.pdf](#)

Norwegian

Safety Datasheet

[SPA_MSDS_SDS0190-EC-SPA_2014-04-10.pdf](#)

Spanish

Safety Datasheet

[SWE_MSDS_SDS0190-EC-SWE_2014-02-21_SDS190ECW.pdf](#)

Swedish

Safety Datasheet

[DUT_MSDS_SDS0190-EC-DUT_2014-04-10.pdf](#)

Dutch

Safety Datasheet

[DAN_MSDS_SDS0190-EC-DAN_2014-04-10.pdf](#)

Danish

Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type
Features

Molded Part Type : **D Subminiature Boot**
Angle : **Straight**
Adhesive Description : **Unicure Pre-Coated Epoxy Adhesive**
Sealable : **Yes**
Product Type : **Molded Boot**

Body Features

Material Code : **25**
Adhesive Pre-Coating : **With**
Material : **Fluid Resistant Modified Elastomer**
Material Systems Code : **25**

Dimensions

Connector Width : **10.7 mm [.421 in]**
Connector Length : **42 – 42.2 mm [1.654 – 1.661 in]**

Usage Conditions

Operating Temperature Range (°F): **-103 – 302**

Other

Adhesive Options : **/225 Precoat**
Comment : **Use only with DR-25 tubing.**
Adhesive Code : **225**

EU RoHS
Directive
2011/65/EU

This declaration covers EU Directive 2011/65/EU incl. Delegated Directive 2015/863/EU. The restrictions under 2015/863/EU apply as of 22 July 2021 for EEE categories 8 (medical devices) and 9 (monitoring and control equipment).

EU ELV Directive
2000/53/EC

China RoHS 2
Directive MIIT
Order No 32, 2016

EU REACH
Regulation (EC)
No. 1907/2006

Current ECHA Candidate List: **JAN 2019 (197)**
Candidate List Declared Against: **JAN 2019 (197)**

Halogen Content

Solder Process
Capability

Not applicable for solder process capability

Statement of
Compliance

[Statement of Compliance pdf](#)

Compliance
Documents

There may be Environmental Compliance related documents on the [DOCUMENTATION Tab](#)

Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for

cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Products with Similar Specs

[View All Similar Products](#)


THIS PRODUCT

TOP RESULTS

D-SUB CONNECTOR BOOTS

[214A032-25/225-0](#)

214A032-25/225-0

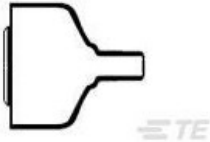

Non-Stocked


Angle : **Straight**

Adhesive Pre-Coating : **With**
 Adhesive Description : **Unicure Pre-Coated Epoxy Adhesive**
 Sealable : **Yes**

D-SUB CONNECTOR BOOTS

[214A021-25/225-0](#)

214A021-25/225-0

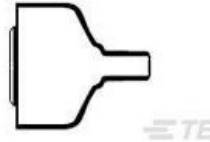

Non-Stocked


Angle : **Straight**

Adhesive Pre-Coating : **With**
 Adhesive Description : **Unicure Pre-Coated Epoxy Adhesive**
 Sealable : **Yes**

D-SUB CONNECTOR BOOTS

[234A032-25/225-0](#)

234A032-25/225-0

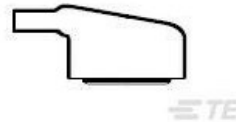

Non-Stocked

Angle : **90°**

Adhesive Pre-Coating : **With**
 Adhesive Description : **Unicure Pre-Coated Epoxy Adhesive**
 Sealable : **Yes**

D-SUB CONNECTOR BOOTS

[214A011-25/225-0](#)

214A011-25/225-0



In-Stock

Angle : **Straight**

Adhesive Pre-Coating : **With**
 Adhesive Description : **Unicure Pre-Coated Epoxy Adhesive**
 Sealable : **Yes**

[ABOUT TE CONNECTIVITY](#)

[FOR PARTNERS](#)

[SUPPORT](#)

[CALL US](#)

[LIVE CHAT](#)

[UNITED STATES \(EN\)](#)