


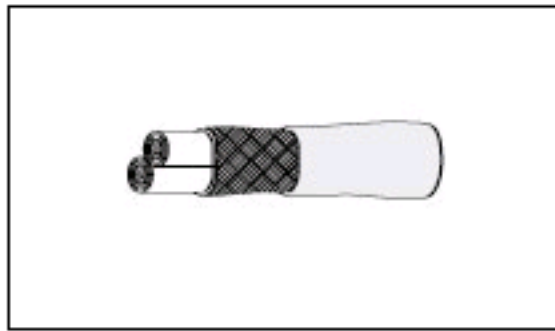

44A1121-20-9/9-9 Product Details

[Share](#) | [Print](#) | [Email](#)


44A1121-20-9/9-9

TE Internal Number: 3820013001

Active

Spec 44, Spec 55 and Spec RCW Wire and Cable

Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Cable Type = Spec 44
- Wire Source = United Kingdom
- Cable Style = Jacketed, Round-Braid Shielded
- Wire Size (AWG/CM) = 20 AWG
- Voltage Rating = 600 VAC

[View all Features](#)

Quick Links

- ▶ [Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

Documentation & Additional Information

Product Drawings:

- None Available

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Cable Type](#) = Spec 44
- [Cable Style](#) = Jacketed, Round-Braid Shielded

Electrical Characteristics:

- [Voltage Rating \(VAC\)](#) = 600

Dimensions:

- [Conductor Outer Diameter \(mm \[in\]\)](#) = 1.01 [0.040]

Body Features:

- [Wire Size \(AWG/CM\)](#) = 20 AWG
- [Cable Jacket Color](#) = White
- [Conductor Type](#) = Tin-Plated Copper
- [Wire Color](#) = White
- [Nominal Outside Diameter \(mm \[in\]\)](#) = 3.76 [0.148]
- [Wire Diameter \(mm \[in\]\)](#) = 1.40 [0.055]

Configuration Features:

- [Number of Conductors](#) = Twisted Pair

Industry Standards:

- [Government/Industry Qualification](#) = No
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- [RoHS/ELV Compliance History](#) = Always was RoHS compliant

Conditions for Usage:

- [Temperature Range \(°C\)](#) = -65 - +150
- [Wire Size - Details](#) = 20 AWG 0.62 mm², 0.00095 in², 19 x 32 AWG

Operation/Application:

- [Application](#) = General Purpose - Lightweight

Packaging Features:

- [Wire Source](#) = United Kingdom
- [Shield \(Screen\) Diameter \(mm \[in\]\)](#) = 3.35 [0.132]

Other:

- [Brand](#) = Raychem

Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)

Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

Keep Me Informed

Receive TE News, Events & Technology Updates

[▶](#)

