


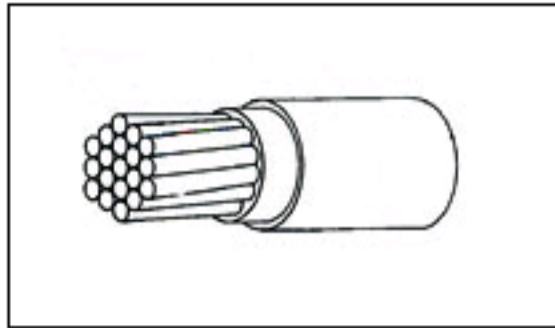

22759/43-24-9 Product Details

[Share](#) | [Print](#) | [Email](#)


22759/43-24-9

TE Internal Number: 393687-000

Active

Spec 44, Spec 55 and Spec RCW Wire and Cable

Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Cable Type = Spec 55
- Wire Source = United States
- Cable Style = Primary
- Wire Size (AWG/CM) = 24 AWG
- Voltage Rating = 600 VAC

[View all Features](#)

[Add to My Part List](#) | [Request Sample](#) | [Find Similar Products](#) | [Buy Product](#)

Quick Links

- ▶ [Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [WIRE, RADIATION-CROSSLINKED, MODIFIED ETFE-INSULATED...](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Cable Type = Spec 55
- Cable Style = Primary

Electrical Characteristics:

- Voltage Rating (VAC) = 600

Dimensions:

- Conductor Outer Diameter (mm [in]) = 0.61 [0.024]

Body Features:

- Wire Size (AWG/CM) = 24 AWG
- Conductor Type = Silver-Plated Copper
- Wire Color = White
- Nominal Outside Diameter (mm [in]) = 1.14 [0.0448]
- Wire Diameter (mm [in]) = 1.14 [0.0448]

Configuration Features:

- Number of Conductors = 1

Industry Standards:

- Government/Industry Qualification = Yes
- Government/Industry Part Number = M22759/43-24-9
- RoHS/ELV Compliance = RoHS compliant, ELV compliant
- Lead Free Solder Processes = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Conditions for Usage:

- Temperature Range (°C) = -65 - +200
- Wire Size - Details = 24 AWG 0.24 mm², 0.00037 in², 19 x 36 AWG

Operation/Application:

- Application = Airframe - Medium Weight

Packaging Features:

- Wire Source = United States

Other:

- Brand = Raychem

Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)

Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

Keep Me Informed

Receive TE News, Events & Technology Updates

[>](#)

