


## D-602-44 Product Details

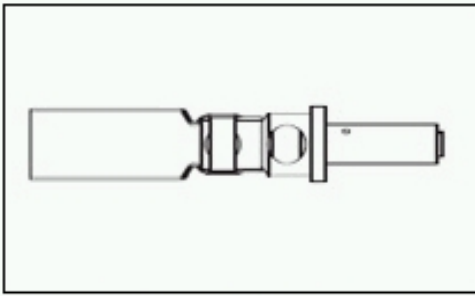

### D-602-44

TE Part Number: 601035-000

 **Active**

 [Add to Part List](#)

### Contacts (SolderTact)

[Not EU RoHS or ELV Compliant](#)

#### Product Highlights:

- MIL-C-28748 Series
- Contact Size = 16
- Polarity = Pin
- Cable Type = Coaxial

[View all Features](#) | 
 [Find Similar Products](#)

### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

**NEW!**

### Documentation & Additional Information

#### Product Drawings:

- [Shielded Contact, Pin Coaxial Cable](#) (PDF, English)

#### Catalog Pages/Data Sheets:

- [Wire and Cable, Harnessing and Protection Products](#) (PDF, English)

#### Product Specifications:

- None Available

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files:

- None Available

#### Related Products:

- [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- Connection Type = Solder

#### Body Related Features:

- [Series](#) = MIL-C-28748
- [Polarity](#) = Pin

#### Contact Related Features:

- [Contact Size](#) = 16

#### Configuration Related Features:

- [Cable Type](#) = Coaxial

#### Industry Standards:

- Government/Industry Qualification = No
- [RoHS/ELV Compliance](#) = Not ELV/RoHS compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process

#### Conditions for Usage:

- Operating Temperature (Max.) (°C) = 150

#### Operation/Application:

- Application Type = Shielded contacts

#### Other:

- Brand = Raychem