


101A052-25-0 Product Details

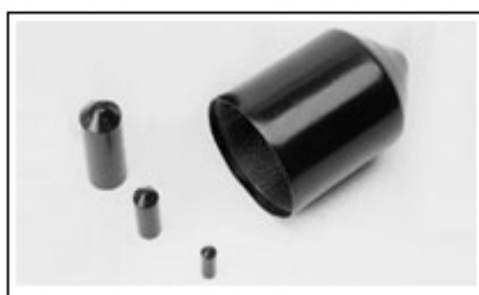

101A052-25-0

TE Part Number: 897163-000

 [Active](#)

 [Add to Part List](#)

Molded Parts

 [Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- End Cap
- Family Name = 101A0
- General Purpose Application
- 25 Material Code
- Adhesive Code = S1017, S1048, S1125

[View all Features](#) | [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [Cap, Round End](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = End Cap
- Size = 52
- Material = Fluid Resistant Modified Elastomer

Electrical Characteristics:

- Expanded ID, Min. (mm [in]) = 20.60 [9.400]
- Recovered ID, Max. (mm [in]) = 9.40 [0.370]

Body Related Features:

- Wall Thickness - Full Recovery (Nominal) (mm [in]) = 2.03 [0.080]
- Length (M [ft]) = 0.061 [0.20]

Contact Related Features:

- [Family Name](#) = 101A0

Housing Related Features:

- Adhesive Pre-Coating = Without
- Adhesive Description = Adhesive Purchased Separately.

Configuration Related Features:

- Material Code = 25
- Adhesive Code = S1017, S1048, S1125

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Operation/Application:

- Application = General Purpose

Other:

- Brand = Raychem