



↓ **PRODUCT DRAWING**
English

> [See All Documentation](#)

TE CONNECTIVITY (TE) - [Raychem](#) | [RC](#) , [SP](#)

44A1121-24-2/6-9

✓ **ACTIVE**

44A1121-24-2/6-9-MX

TE Internal Number: 382335-000

Alias ID: 8-1192861-0

Get a Sample

Compatible Parts & Tooling

[Add to List](#) ▼ ▼ | [Documents](#) | [Features](#) | [Compliance](#) | [Similar Products](#)

North America ▼

DISTRIBUTOR	PHONE	STOCK	DATE AS OF	
NEWARK ELEMENT14	1-800-463-9275	2	2018/01/09	Visit Site
MASTER ELECTRONICS CORP.	1-888-473-5297	1,380	2018/01/07	Visit Site
View More Distributors (2)				

DOCUMENTATION | [FEATURES](#) | [PRODUCT COMPLIANCE](#)

Product Drawings

[CABLE, RADIATION-CROSSLINKED, POLYALKENE-INSULATED, TWO CONDUCTOR, SHIELDED, JACKETED, LIGHTWEIGHT, GENERAL PURPOSE](#)

PDF **(TIFF AVAILABLE)**

English

[TWO CONDUCTOR CABLE, RADIATION-CROSSLINKED, POLYALKENE-INSULATED, SHIELDED, JACKETED, LIGHTWEIGHT, GENERAL PURPOSE, 600 VOLT](#)

PDF **(TIFF AVAILABLE)**

English

Product Specifications

Product Specification

[Wire And Cable, Electric, Radiation-Crosslinked, Polyalkene-Insulated, Copper Or Copper Alloy](#)

PDF

English

Product Type Features	Cable Type	Spec 44
	Shielded	Yes
	Cable Style	Jacketed, Round Braided
	Product Type	Cable
	Product Classification	Cable - High Performance - Spec 44, 55 & RCW

Configuration Features	Number of Strands	19
	Number of Conductors	2

Electrical Characteristics	Voltage Rating (V)	600
----------------------------	--------------------	------------

Body Features	Shield Material	Tin-Coated Copper
	Insulation Material	Radiation-Crosslinked, Polyalkene
	Jacket Color	White
	Wire Color	Blue, Red
	Conductor Material	Tin-Plated Copper
	Shield Diameter	2.59 mm [.102 in]

Dimensions	Conductor Diameter	.64 mm [.025 in]
	Strand Size (AWG)	36
	Overall Outside Diameter	3 mm [.118 in]
	Wire Size (AWG)	24
	Wire Size (mm ²)	.205
	Wire Diameter	1.02 mm [.04 in]

Usage Conditions	Operating Temperature Range (°C)	-65 – 150
------------------	----------------------------------	------------------

Other	Wire Source	United States
-------	-------------	----------------------

Statement of Compliance [Statement of Compliance PDF](#)



Also in the Series | [RC](#)



Between Series Adapters (1)



Board-to-Board Headers & Receptacles (130)



Box Mount D-Sub Connectors (1)



High Speed Backplane Connectors (1)




He

Also in the Series | [SP](#)




Board-to-Board Connector Contacts (2)

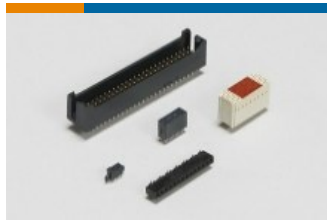

Board-to-Board Headers & Receptacles (1)



Cable Actuated Position Sensors (17)

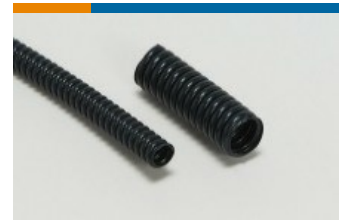

Convuluted Tubing (15)



He

Customers Also Bought

SOLDERSLEEVE SHIELD TERMINATORS




SO63-3-55-24-90
SO63-3-55-24-90

MULTICORE CABLE



44A1121-24-2/6-9-CA
44A1121-24-2/6-9-CA

MULTICORE CABLE

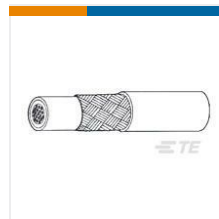

44A1111-24-9-9-CA
44A1111-24-9-9-CA

MULTICORE CABLE



44A1121-22-2/6-9-CA
44A1121-22-2/6-9-CA

[Our Company](#)

[Events](#)

[TE News Center](#)

[Careers](#)

[Investors](#)


[Corporate Responsibility](#)

[Terms and Conditions of Sale](#)

[Distributors](#)

[Suppliers](#)

 [Email or Call Us](#)

 [Find Authorized Distributors](#)

 [What's New on TE.com](#)

 [Product FAQs](#)

Select Country & Language

[United States \(EN\)](#)

[Germany \(DE\)](#)

[China \(中文\)](#)

[Japan \(日本語\)](#)

[Afghanistan \(EN\)](#) ▼

[Find Your Country](#) ▼

[Terms of Use](#) | [Privacy](#) | [Cookie Policy](#) | [Accessibility](#) | [Site Map](#)



© 2018 TE Connectivity. All Rights Reserved.