




HARNESSING

HEAT SHRINK BOOTS

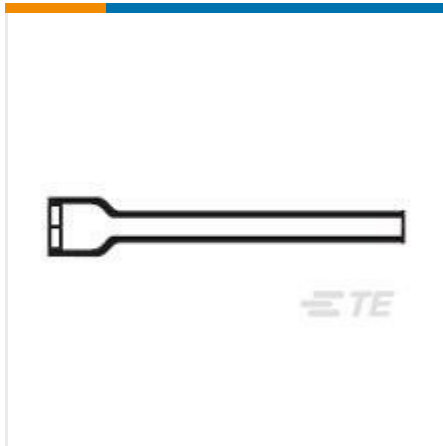

✓ Active

TE CONNECTIVITY (TE)

202F232-51-22/164-0

Raychem | CAP

202F232-51-22/164-0

TE Internal Number: 721355-000

Alias ID: 6-1195640-9

EU RoHS Compliant

EU ELV Compliant

Lipped Yes

Operating Temperature Range (°C) -55 – 105

Material Systems Code 20

Adhesive Pre-Coat Yes

↓ **PRODUCT DRAWING**
English

DOCUMENTATION

Product Drawings

Boot, Straight, With Lip

PDF

English

Product Specifications

Product Specification

Thermofit Elastomeric Polymer Blend Molded Components Flame Resistant, Flexible, Heat-Shrinkable

PDF

English

FEATURES

Please Note: Use the Product Drawing for all design activity.

Product Type Features

Molded Part Type Molded Boot

Configuration Features

Lipped Yes

Body Features

Material Systems Code 20

Adhesive Pre-Coat Yes

Material Polymer Blend Flexible Elastomeric (EPB)

Dimensions

Inside Diameter as Supplied 31 mm [1.22 in]

Usage Conditions

Operating Temperature Range (°C) -55 – 105

Operation/Application

Power Cable Accessory No

Industry Standards

Government Qualified No

Approved Standards SC-X-15112

Other

Adhesive Type High Melt Point Pre-Coat Adhesive

Statement of Compliance

Statement of Compliance

PDF