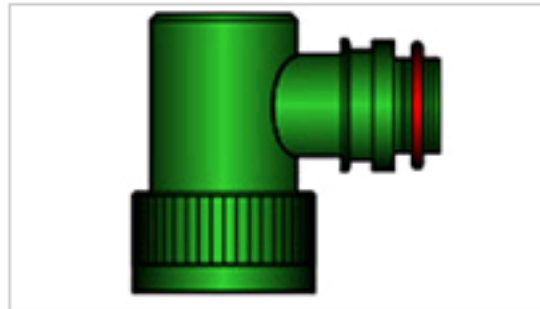


STXR40AB90-0805AI Product Details

[Share](#) | [Print](#) | [Email](#)


✓ Active

Braid, Fixed, Spin and Tinel Lock Adapters

STXR40AB90-0805AI
STXR40AB90-0805AI
 TE Internal Number: 423891-000

Product Highlights [View All](#)

- Applies To Cable
- Military Style Number = MIL-DTL-38999
- Style = Tinel Lock
- Connector Code = 40
- 90°

- [Pricing & Availability](#)
- [Request Sample](#)
- [Add to My Part List](#)
- [Buy Product through Distributor](#)

Feedback

[Documents](#) | [Features](#) | [Compliance](#)

Please Note:
 Use the Product Drawing for all design activity

Product Type Features	
Style ?	Tinel Lock
Angle ?	90°
Connector Shell Size	8
Finish	Cadmium Plating over Electroless Nickel
Color	Olive Drab
Dimensions	
Boot Diameter (mm [in]) ?	15.54 [0.612]
Cable Diameter Range (mm [in])	4.50 - 7.10 [0.180 - 0.280]
Body Features	
Connector Code ?	40
Entry Size	5
Material	Aluminum Alloy

Configuration Features	
Braid ?	Single 36 AWG Braid
Industry Standards	
Government/Industry Qualification	No
Military Style Number	MIL-DTL-38999
RoHS/ELV Compliance ?	Not ELV/RoHS compliant
Lead Free Solder Processes ?	Not relevant for lead free process
Conditions for Usage	
Applies To	Cable
Other	
Brand	Raychem
Comment	For specific shell size information, refer to "Hardware" or Catalog.

Related Products

Not quite the product you're looking for?
[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)
- [Global Accessibility Statement](#)

Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

Keep Me Informed

