


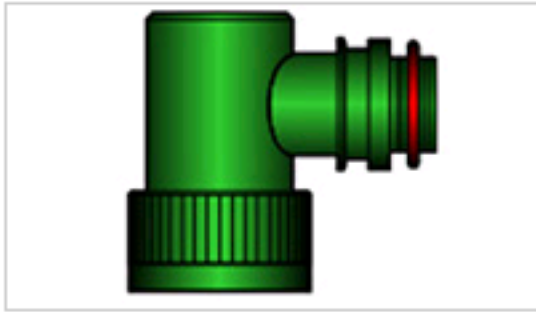

TXR76AU90-1006AI Product Details

[Share](#) | [Print](#) | [Email](#)


✓ Active

Braid, Fixed, Spin and Tinel Lock Adapters

TXR76AU90-1006AI

TXR76AU90-1006AI

TE Internal Number: D15566-000

Product Highlights [View All](#)

- Applies To Cable
- Style = Tinel Lock
- Connector Code = 76
- 90°
- Connector Shell Size = 10

[Pricing & Availability](#)

[Request Sample](#)

[Add to My Part List](#)

[Buy Product through Distributor](#)

Feedback

[Documents](#) | [Features](#) | [Compliance](#)

Please Note:

Use the Product Drawing for all design activity

Product Type Features	
Style [?]	Tinel Lock
Angle [?]	90°
Connector Shell Size	10
Finish	Zinc Cobalt over Electroless Nickel
Color	Olive Drab
Dimensions	
Boot Diameter (mm [in]) [?]	17.14 [0.675] ▾
Cable Diameter Range (mm [in])	4.50 - 8.70 [0.180 - 0.340]
Body Features	
Connector Code [?]	76
Entry Size	6
Material	Aluminum Alloy

Configuration Features	
Braid [?]	Single 36 AWG Braid
Industry Standards	
Government/Industry Qualification	No
RoHS/ELV Compliance [?]	Not ELV/RoHS compliant
Lead Free Solder Processes [?]	Not relevant for lead free process
Conditions for Usage	
Applies To	Cable
Other	
Brand	Raychem
Comment	For specific shell size information, refer to "Hardware" or Catalog.

Related Products

Not quite the product you're looking for?

[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)
- [Global Accessibility Statement](#)

Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

Keep Me Informed

