

Product Compliance


For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	有害物质含量符合标准要求 No Restricted Substance(s) Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2025 (250) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Customers Also Bought

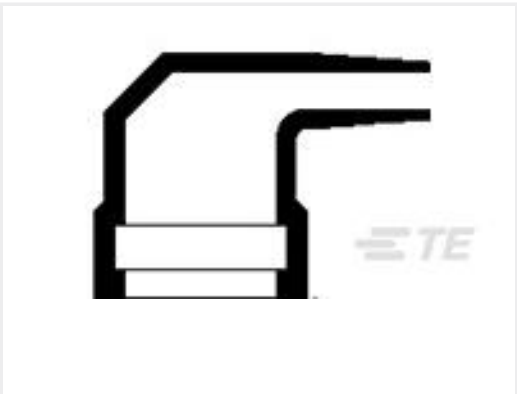


TE Part #087454-000
224W221-25-0



TE Part #ASL006-05PN-HE
RECEPT.ASSY. 2 HOLE MNT.MICRO MK3



TE Part #CAT-R2137-RW200E
Single Heavy Wall RW 200 E: Heat Shrink Tubing, 2:1 Shrink Ratio

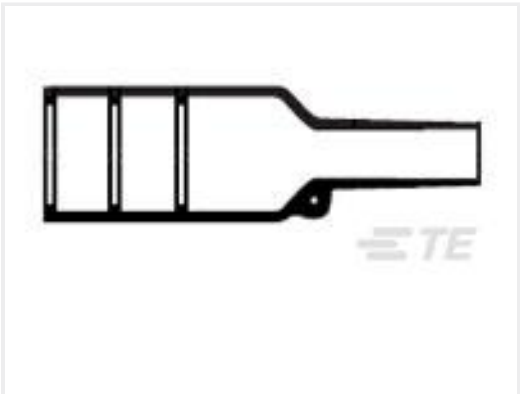

TE Part #396040-000
202K111-25-0




TE Part #AS010-98PN
RECEPT.2 HOLE MNT.TYPE 0




TE Part #DT04-2P-CE09
REC, 2P, BLK, E, XCAP



TE Part #2161243004
55A0111-20-0

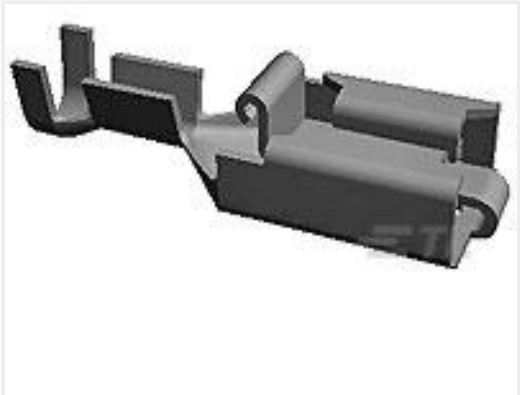

TE Part #1-160759-1
250 PL MKI REC. 20-15AWG PTBR

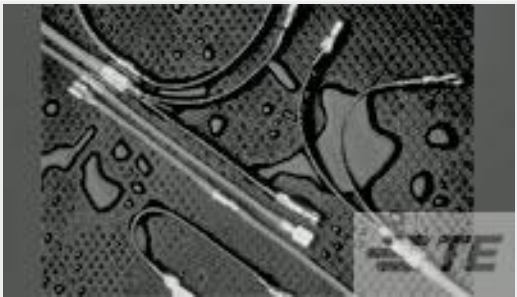

TE Part #CC2636-000
B-106-1602CS100

Documents

Product Drawings
B-106-1502CS100

English

Datasheets & Catalog Pages
1654025_Sec8_B-106

English

Product Specifications
Installation Procedure for Duraseal Splices and Terminals

English