


TXR61AB00 - 1810AI Product Details

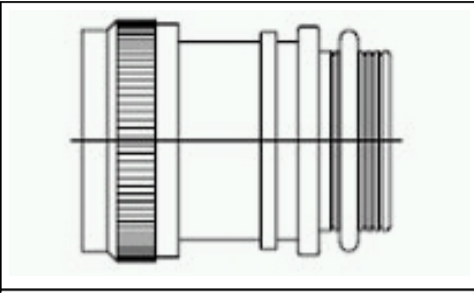

TXR61AB00 - 1810AI

Braid, Fixed, Spin and Tinel Lock Adapters

[Not EU RoHS or ELV Compliant](#)

Product Highlights:

- ? Style = Tinel Lock
- ? Connector Code = 61
- ? Straight
- ? Shell Size = 18, F
- ? Entry Size = 10

[View all Features](#) | [Find Similar Products](#)

TE Part Number: 533279 - 000

[Active](#)

[Add to Part List](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [Tinel -Lock Adapter](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? None Available

Application Specifications:

- ? None Available

Instruction Sheets:

- ? None Available

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features

(Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Style](#) = Tinel Lock
- ? [Shell Size](#) = 18, F
- ? Material = Aluminum Alloy
- ? Finish = Cadmium Plating over Electroless Nickel
- ? Color = Olive Drab

Electrical Characteristics:

- ? [Angle](#) = Straight
- ? [Entry Size](#) = 10
- ? [Boot Diameter \(mm \[in\]\)](#) = 23.49 [0.925]
- ? [Entry Diameter \(mm \[in\]\)](#) = 15.87 [0.625]
- ? Finish Code = B

Body Related Features:

- ? [Connector Code](#) = 61
- ? [Cable Diameter \(Max.\) \(mm \[in\]\)](#) = 15.37 [0.605]

Configuration Related Features:

- ? [Braid](#) = Single 36 AWG Braid
- ? Material Code = A

Industry Standards:

- ? [RoHS/ELV Compliance](#) = Not ELV/RoHS compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process

Other:

- ? Brand = Raychem