



Description

6 figure (non-reset), AC hour meter encased in a rugged steel housing. The non-reset models are completely sealed.

Features

- Rugged steel housing

Options

- Chrome bezel
- Readouts to 9999.99 hrs.
- Gasket (721-0004)

Specifications

Figures: 6 figure (non-reset), 0.19" [5mm] high, 99,999.9 (non-reset)
Reset: Non-reset
Voltages: 115VAC (+/- 10%), 60Hz.
Power: 3 watts max.

Mounting: Panel (3-hole or metal clamp)
Termination: 6" [152mm] wire leads
Temp. Range: -40°F to +160°F [-40°C to +70°C]
Approvals: UL Recognized, CE Compliant, ROHS
Weight: 10 oz. [284g]

Models Description


Models	Description
720-0007	115VAC/60Hz, non-reset, 3-hole round, 6" [152.4mm] wire leads
720-0011	115VAC/60Hz, non-reset, metal clamp, 6" [152.4mm] wire leads

Models Description

* Items in bold are normally in factory stock.

Dimensions


Non-Reset / Terminal Block

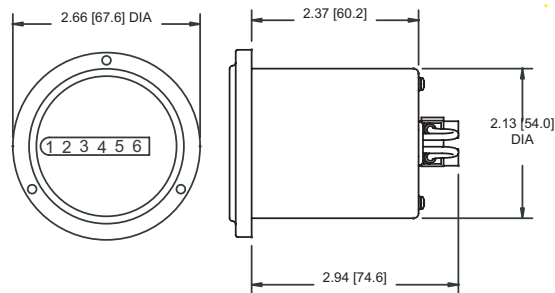


Panel cutout: 2.16" [54.9] Dia.
 Mounting holes: 0.125" [3.2] Dia. on 2.44" [62.0] B.C.

Applications

Control panels

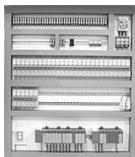

Industrial equipment

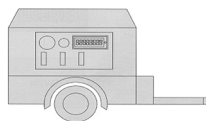

Test equipment

