

## Data sheet

### Modul surface mount housing 8 port pure white


P/N

130861-0802-E


EAN 4250184132981

2015-29-06


## Illustrations

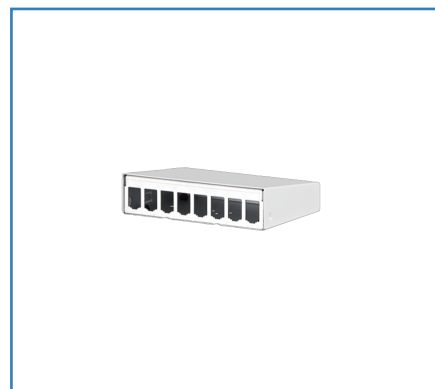

Dimensional drawing

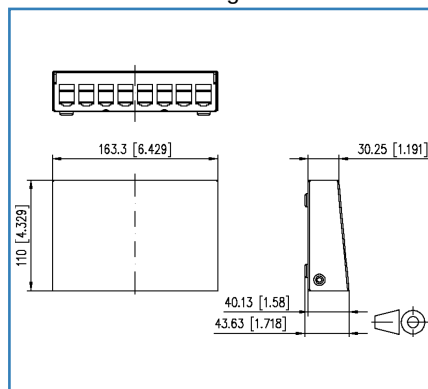

Cut-out

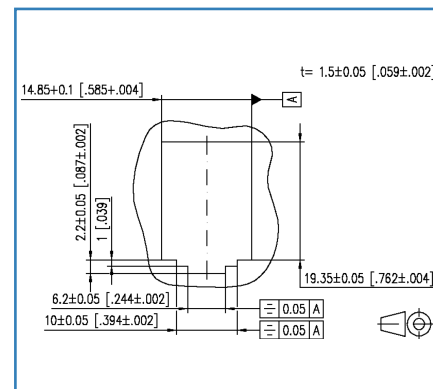

See enlarged drawings at the end of document

## Product specification

- surface-mounted, unequipped module housing for individual modules in modul design
- solid steel sheet housing
- upper part of the housing powder-coated in RAL 9010
- upper part of the housing can be put on and removed easily because no screws are used for fastening
- equipotential bonding possible by means of contact pin
- additional strain relief on lower part of housing using cable ties
- suitable for direct wall mounting, as desktop device and for DIN-rail mounting using the DIN rail adapter mini FS
- bottom of the 3-port and 4-port housing can be removed. Additional fastening by means of 60 mm fastening clearance.
- optionally available and fits in all housings: mini splice tray
- optionally available 2 x 12 housing: Strain relief for patch cords 130861-24ZE-E
- variants: 3, 4, 6, 8, 12, 16 and 2 x 12 ports



## Data sheet

Page 2/5

## Modul surface mount housing 8 port pure white

P/N

130861-0802-E

EAN 4250184132981

2015-29-06

## Technical Data

## General Data

Fields of application

Office

Design

patch panel

Color

pure white

Dimensions

Dimension (L x W x H)

110.00 x 163.30 x 43.63 mm

Dimension (L x W x H)

4.33 x 6.43 x 1.72 in.

Modularity

yes

Labeling option

on housing

## Connections/interfaces

Number of ports interface 1

8

Number of equipped ports interface 1

0

Number of ports interface 2

8

Number of ports interface 2 equipped

0

## Mechanical characteristics

Cut-out

Modul

Strain relief

cable tie

## Materials and material properties

Material - Housing

aluminium-zinc sheet

Material - Front cover

aluminium-zinc sheet

Material - Cover

steel

## Environmental conditions

Temperature (min. - max.)

Temperature - Storage °C

-40 - 70 °C

Temperature - Storage °F

-40 - 158 °F

Temperature - Operating °C

-40 - 70 °C

Temperature - Operating °F

-40 - 158 °F



## Data sheet

Page 3/5

# Modul surface mount housing 8 port pure white

P/N

130861-0802-E

EAN 4250184132981

2015-29-06

## Technical Data

### Certifications

Gost Certification yes

### Approvals

RoHS compliant

### Classifications

ETIM 5.0 EC001128

### Packing details

|                                 |                            |
|---------------------------------|----------------------------|
| Type of packaging               | 1 pc(s) / box              |
| Packaging unit - Weight (gram)  | 420.00 g                   |
| Packaging unit - Weight (pound) | 0.93 lb                    |
| Packaging dimension (W x H x D) | 135.00 x 133.00 x 52.00 mm |
| Packaging dimension (W x H x D) | 5.31 x 5.24 x 2.05 in.     |



Data sheet

Page 4/5

## Modul surface mount housing 8 port pure white

P/N

130861-0802-E

EAN 4250184132981

2015-29-06


### Accessories

| P/N          | Designation                                       |
|--------------|---------------------------------------------------|
| 130861-MSK-E | FO extension set for module surface mount housing |



## Illustrations

Dimensional drawing

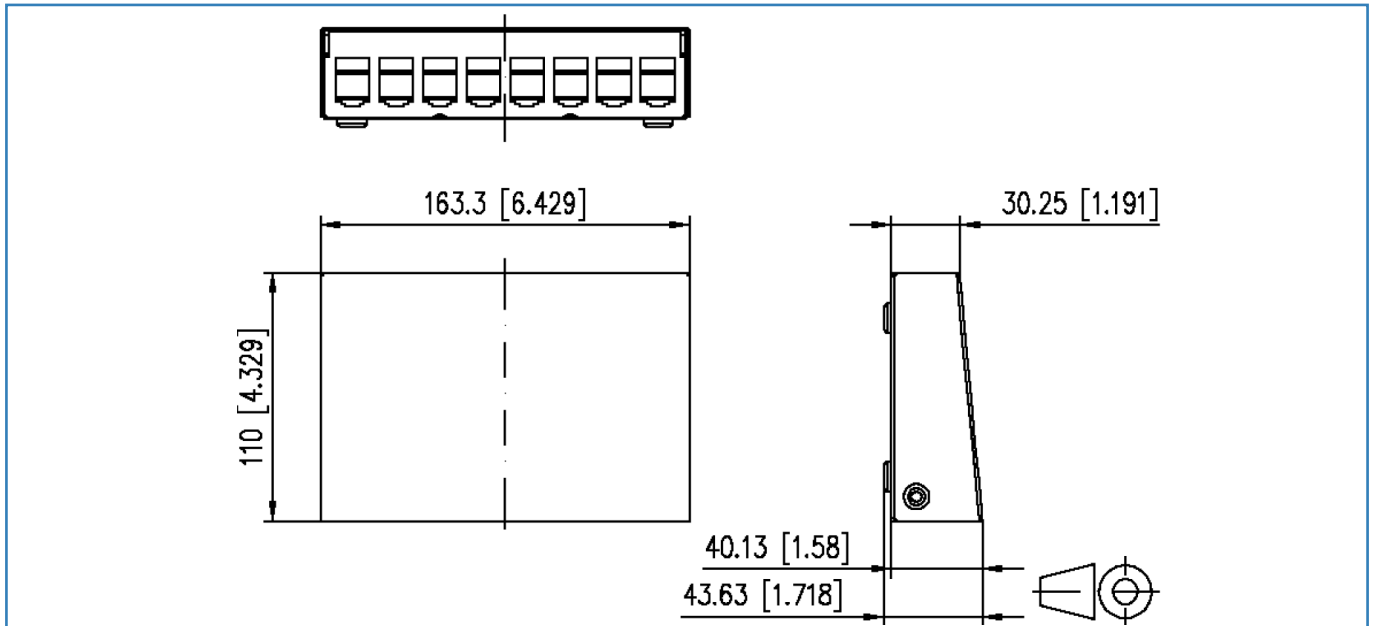

Cut-out

