

Data sheet

Modul surface mount housing 12 port pure white


P/N

130861-1202-E


EAN 4250184114420

2015-29-06


Illustrations

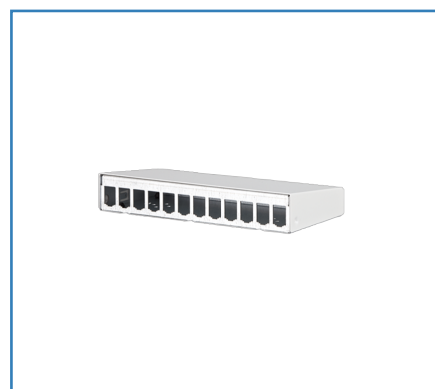

Dimensional drawing

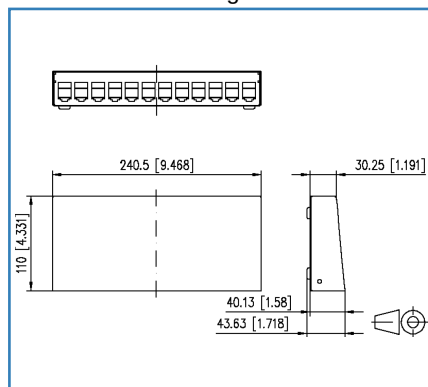

Cut-out

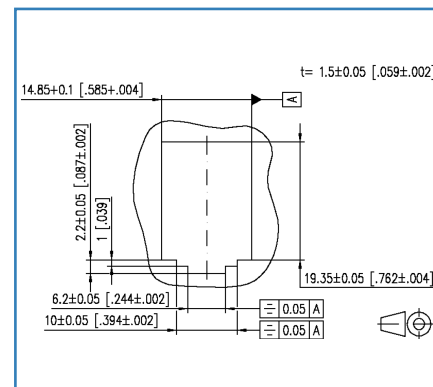

See enlarged drawings at the end of document

Product specification

- surface-mounted, unequipped module housing for individual modules in modul design
- solid steel sheet housing
- upper part of the housing powder-coated in RAL 9010
- upper part of the housing can be put on and removed easily because no screws are used for fastening
- equipotential bonding possible by means of contact pin
- additional strain relief on lower part of housing using cable ties
- suitable for direct wall mounting, as desktop device and for DIN-rail mounting using the DIN rail adapter mini FS
- bottom of the 3-port and 4-port housing can be removed. Additional fastening by means of 60 mm fastening clearance.
- optionally available and fits in all housings: mini splice tray
- optionally available 2 x 12 housing: Strain relief for patch cords 130861-24ZE-E
- variants: 3, 4, 6, 8, 12, 16 and 2 x 12 ports



Data sheet

Page 2/5

Modul surface mount housing 12 port pure white

P/N

130861-1202-E

EAN 4250184114420

2015-29-06

Technical Data

General Data

Fields of application

Office

Design

patch panel

Color

pure white

Dimensions

Dimension (L x W x H)

110.00 x 240.50 x 43.63 mm

Dimension (L x W x H)

4.33 x 9.47 x 1.72 in.

Modularity

yes

Labeling option

on housing

Connections/interfaces

Number of ports interface 1

12

Number of equipped ports interface 1

0

Number of ports interface 2

12

Number of ports interface 2 equipped

0

Mechanical characteristics

Cut-out

Modul

Strain relief

cable tie

Materials and material properties

Material - Housing

aluminium-zinc sheet

Material - Front cover

aluminium-zinc sheet

Material - Cover

steel

Environmental conditions

Temperature (min. - max.)

Temperature - Storage °C

-40 - 70 °C

Temperature - Storage °F

-40 - 158 °F

Temperature - Operating °C

-40 - 70 °C

Temperature - Operating °F

-40 - 158 °F



Data sheet

Page 3/5

Modul surface mount housing 12 port pure white

P/N

130861-1202-E

EAN 4250184114420

2015-29-06

Technical Data

Certifications

Gost Certification yes

Approvals

RoHS compliant

Classifications

ETIM 5.0 EC001128

Packing details

Type of packaging	1 pc(s) / box
Packaging unit - Weight (gram)	588.00 g
Packaging unit - Weight (pound)	1.30 lb
Packaging dimension (W x H x D)	263.00 x 135.00 x 50.00 mm
Packaging dimension (W x H x D)	10.35 x 5.31 x 1.97 in.



Data sheet

Page 4/5

Modul surface mount housing 12 port pure white

P/N

130861-1202-E

EAN 4250184114420

2015-29-06

Accessories

P/N	Designation
130861-MSK-E	FO extension set for module surface mount housing



Modul surface mount housing 12 port pure white

P/N


130861-1202-E

EAN 4250184114420

2015-29-06

Illustrations

Dimensional drawing

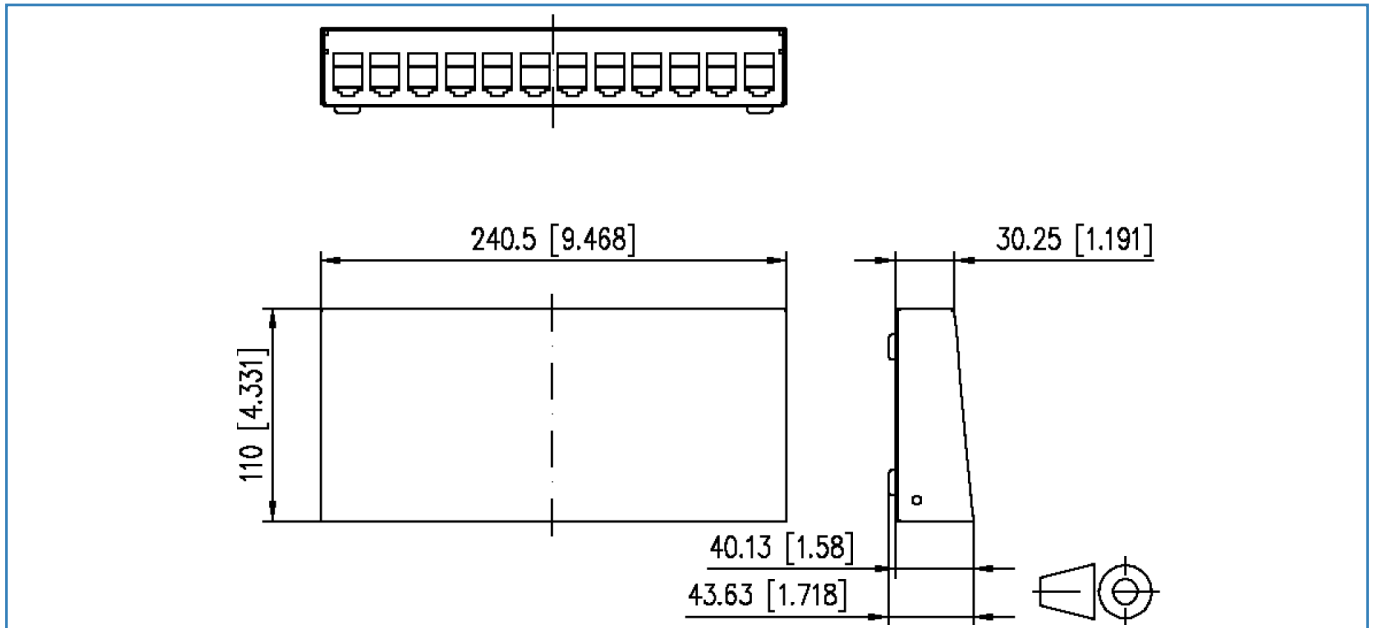

Cut-out

