

Data sheet

OpDAT 24 PF 1RU patch panel fixed installation for 24xST, unequipped

Page 1/5

P/N

1502000100-E


EAN 4250184108115

2015-06-07

Illustrations



Dimensional drawing

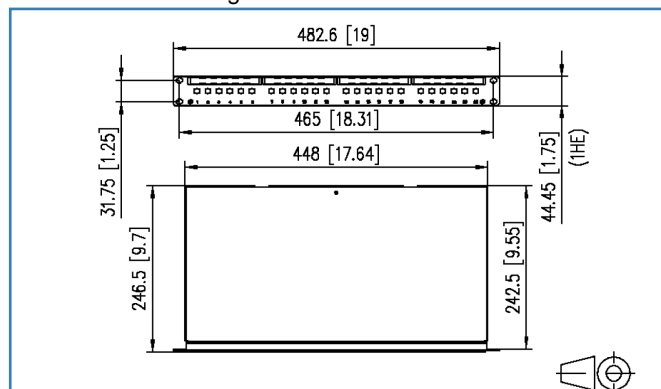

See enlarged drawings at the end of document

Product specification

- 19 inch 1RU fiber optic patch panel for fixed installation
- unequipped
- light aluminum construction
- removable front plate for easy adapter mounting
- variable cable entry (straight / inclined) from both sides possible
- cable relief with supplied cable tie or optional cable screw gland also possible.
- cable diameter from 3 to 20 mm
- strain relief for central element / Kevlar
- cable management by means of freely positionable guide elements
- snap-on cover for easy access during service work
- label window for enclosed identification labels

variants:

24x LC-D

24x SC-D

24x ST

matching recesses

LC-D, SC simplex, E2000 simplex

SC-D, Q-LC

ST, FC

OpDAT 24 PF 1RU patch panel fixed installation for 24xST, unequipped

P/N
1502000100-E
EAN 4250184108115

2015-06-07

Technical Data

General Data

Fields of application	Office
Design	patch panel
Color	anodized alu.
Dimensions	
Dimension (L x W x H)	260.90 x 482.60 x 44.45 mm
Dimension (L x W x H)	10.27 x 19.00 x 1.75 in.
Inches	19 inches
Height unit	1RU
Labeling option	label window with identification label + printed numbers

Connections/interfaces

Connector technology interface 1	ST
Number of ports interface 1	24
Number of equipped ports interface 1	0
Connector technology interface 2	ST
Number of ports interface 2	24
Number of ports interface 2 equipped	0
Cable sheath diameter (min. - max.)	
Cable sheath diameter	3.00 - 20.00 mm
Cable sheath diameter	0.12 - 0.79 in.
Cable access/outlet	straight or inclined, on the rear, from the left and right

Mechanical characteristics

Cut-out	ST
Strain relief	cable tie

Materials and material properties

Material - Housing	Al (Aluminium)
Material - Front cover	Al (Aluminium)
Material - Front cover finish	anodized
Material - Cover	Al (Aluminium)

OpDAT 24 PF 1RU patch panel fixed installation for 24xST, unequipped

P/N

1502000100-E

EAN 4250184108115

2015-06-07

Technical Data

Environmental conditions

Temperature (min. - max.)

Temperature - Storage °C -40 - 70 °C

Temperature - Storage °F -40 - 158 °F

Temperature - Operating °C -40 - 70 °C

Temperature - Operating °F -40 - 158 °F

Certifications

Gost Certification yes

Approvals

RoHS compliant

Classifications

ETIM 5.0 EC001130

Packing details

Type of packaging 1 pc(s) / box

Packaging unit - Weight (gram) 1670.00 g

Packaging unit - Weight (pound) 3.68 lb

Packaging dimension (W x H x D) 523.00 x 361.00 x 45.00 mm

Packaging dimension (W x H x D) 20.59 x 14.21 x 1.77 in.

Data sheet

Page 4/5

**OpDAT 24 PF 1RU patch panel fixed installation
for 24xST, unequipped**

P/N

1502000100-E

EAN 4250184108115

2015-06-07

Accessories

P/N	Designation
15090001-I	OpDAT ST coupler SM (ceramic)
1509010000-E	OpDAT splice tray for 12 splices unequipped
899789-01	Label sheet for E-DAT C6 and E-DAT design patch panels
15090031-I	OpDAT ST coupler MM (Ph-Br)



Data sheet

Page 5/5

**OpDAT 24 PF 1RU patch panel fixed installation
for 24xST, unequipped**

P/N

1502000100-E

EAN 4250184108115

2015-06-07

Illustrations

Dimensional drawing

