



SCHROFF

Project - 0 item(s)


MY PROJECT LIST

- PRODUCTS
- APPLICATIONS
- INDUSTRIES
- NEW PRODUCTS
- CONFIGURATORS
- Products ▾
- Search

Home > Side panels type H for stainless steel gaskets

Side panels type H for stainless steel gaskets

SCHROFF

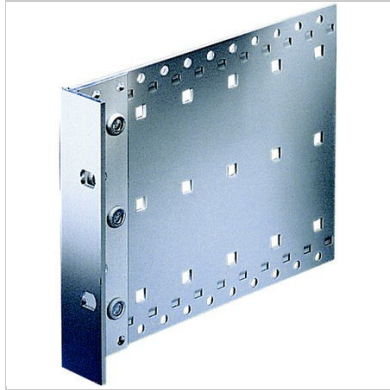

Catalog Number: 24566-431

[Back To Product](#)

- For high mechanical demands, 19" bracket, tox-cold welded, Al, 2 mm, clear passivated, front anodised
- Side panels, type H, EMC sealing, side panel joints, handles, corner profiles, mounting in panels
- Versions for EMC sealing (stainless steel or textile)

Product family:

EuropacPRO

Note:

- Please order front handles separately
- Side panel and 19" bracket are tox-cold welded together. toxen = Clinching technique, without add aids. This takes place with special tools and high pressure.

Type:

Individual Components

Individual Component Type:

Panels & Accessories



Select product specifications before modifying or adding to project list or requesting a quote.

Height-U-defining

Depth-mm-defining

[Clear Selection](#)

Quantity

Add Item to Project List +

Links



Native CAD files


Technical Data

Depth mm	355.0
Qty	PU 1 pair
Description	Without handle holes
Height U	6

Delivery Comprises:

Item	Quantity	Description
1	2	Side panel, Al, 2 mm, Al profile, clear chromated, support bracket: Visible side anodised

 
Accessories



Side panel connecting bracket, between europacPRO subrack and fan, including fixing material kit, PU 4 pieces

21101-954


Add Item to Project List +

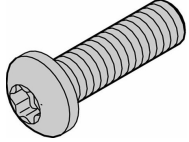

Countersunk screw, torx (M4x10), steel zinc plated, PU 100 pieces

24560-155


[Add Item to Project List +](#)

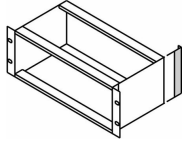

Countersunk screw, torx (M4x10), steel zinc plated, PU 100 pieces

24561-498


[Add Item to Project List +](#)

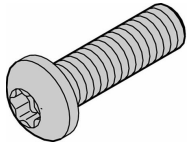

Countersunk screw, torx (M4x14), steel zinc plated, PU 100 pieces

24560-130

 [Add Item to Project List +](#)



Stainless steel EMC gasket, 6 U, 232 mm, stainless steel, 2 pieces necessary per front panel, PU 10 pcs

21101-707

[Add Item to Project List +](#)

EXPLORE

- [About Us](#)
- [Services & Capabilities](#)
- [News & Events](#)
- [Newsletter Subscriptions](#)
- [Strategic Partnerships](#)
- [Investor Relations](#)

CONTACT

- [Customer Service](#)
- [Find a Sales Office or Distributor](#)
- [Global Locations](#)
- [Product Compliance & Certifications](#)
- [Partner Login](#)

DOWNLOAD

- [Download Center](#)
- [Reference Projects](#)
- [Videos](#)
- [Product Configurators](#)
- [Warranties and Terms of Sale & Procurement](#)

© 2018 nVent. All rights reserved | [Privacy Policy](#) | [Terms of Use](#) | [Cookie Policy](#) | [Imprint](#) | [Site Map](#)

Connect With Us

