


## Front panels, U profile, shieldable

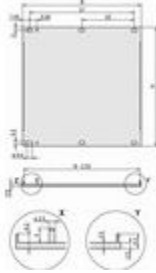

Product illustrations are exemplary illustrations and can deviate from supplied products.

**Part no.:** 30848-359

**Features:**

- High stability through U profile
- Front panel, U profile, Al, front anodised, rear conductive, 2 alignment pins pressed-in, stainless steel
- Differences in the finish between 2 ... 12 HP and 14 ... 84 HP

Add to basket



**Standard pack quantity** 5



**Technical information:**

Height	Height	Width	B	b1	b2	Alignment pin
6 U	261,8 mm	12 HP	60,6 (mm)	45,7 (mm)		x

**Downloads:**

Download CAD data in DWG format ([Log in](#) Required)  
Download CAD data in DXF format ([Log in](#) Required)

To gain access to the additional information you must [Log in](#).  
If you do not yet have a user name, you may [Register here](#).

**Accessories:**

Part no.	Description	
<a href="#">21101-855</a>	Textile EMC gasket 6 U, PU 10 pieces This accessory qualifies for our Front Panel Express service	Add to basket
<a href="#">21101-856</a>	Textile EMC gasket 6 U, PU 100 pieces	Add to basket

**Note:**

- Standard pack quantity:

- 2 to 28 HP: 5 pieces,  
42 to 84 HP: 1 piece,  
supplied in standard pack quantities (SPQ) only
- Please order EMC profile seal and fixing materials separately