

YOU ARE HERE: [Home](#) > [Product Selection](#) > [Strain Relief Fittings](#) > [Nickel Plated Brass](#) > [EMI / RFI Braided / Foil / Elongated](#) > [PG](#) > [CD29CA-BE](#)

SHARE THIS PRODUCT

PRINT

Nickel Plated Brass EMI / RFI Braided / Foil / Elongated Strain Relief Fittings PG

Strain Relief Fittings

Features

Technical Data

Downloads

Approvals

Accessories



1

ADD TO QUOTE

Nickel Plated Brass Feed-Through Elongated PG 29 Standard

Thread Range: PG 29

Locking Nut & O-ring Sold Separately

Sealcon # CD29CA-BE

Cable Range .71" - .98" (18 - 25 mm)

Color Nickel

Hummel # 1.691.2900.01

Hummel HSK-M-EMV

Material Nickel Plated Brass

Hole Diameter (A) | 1.47" (37.3 mm)


Body Length (B) | 1.14" (29 mm)

Thread Length (D) | .31" (8 mm)

Wrench Flat (F1/F) | 1.57" (40 mm)



Suggested Clearance Hole for Non-Threaded Mounting

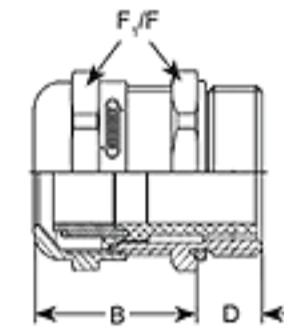

Related Accessories



[Adapter PG 29 to 1" NPT](#)




[Enlarger PG 29 to PG 36](#)



[NPB Locking Nut](#)



[NPB Locking Nut](#)

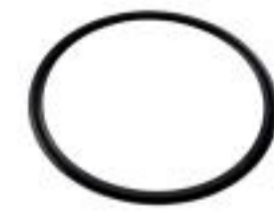

[Buna-N O-Ring](#)



HI-TECH CONTROLS, INC.

Importer of **HENSEL Enclosures** and Accessories!

VISIT OUR SISTER COMPANY
[HI-TECH CONTROLS, INC.](#)

[> Strain Relief Fittings](#) [> Industrial Enclosures](#)

[> Hazloc Cable Glands](#) [> Conduit System](#)

[> Circular Connectors](#) [> Thread Adapters, Enlargers & Reducers](#)

[> Accessories](#)

[> Technical](#)

[> Resources](#)

[> About Us](#)

[> Site Map](#)

[> Copyright](#)

[> Privacy Policy](#)



7374 S. Eagle Street
Centennial, CO 80112-4221 USA

800-456-9012 Toll Free
303-699-1135 Phone
303-680-5344 Fax

[Contact](#)