


M23 POWER, M23 HYBRID CONNECTORS

HOUSINGS

M23 Power Straight Connector, EMI, Female Thread

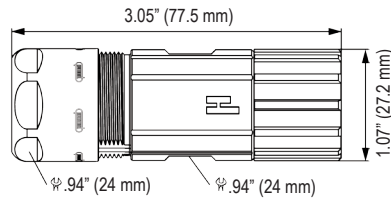


Cable-Ø

Part Number

7 - 12 mm (.27 - .47")	S7.550.500.000
11 - 17 mm (.43 - .67")	S7.550.600.000

M23 Power Straight Connector, EMI, Female Thread Standard Threaded and TWILOCK/TWILOCK-S*- Quick Connect

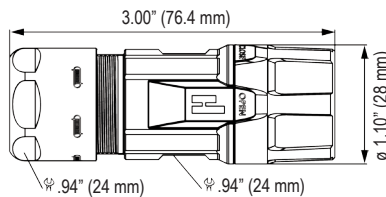

Cable-Ø


Part Number

7 - 12 mm (.24 - .47")	S7.556.500.000
11 - 17 mm (.43 - .67")	S7.556.600.000

*Intermateable with SpeedTEC® (Twilock-S)

7 - 12 mm (.24 - .47")	S7.556.500.00S
11 - 17 mm (.43 - .67")	S7.556.600.00S

M23 Power Straight Connector, EMI, Male Thread Standard Threaded and TWILOCK/TWILOCK-S*- Quick Connect

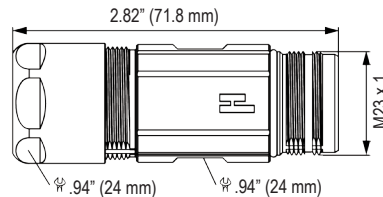

Cable-Ø


Part Number

7 - 12 mm (.27 - .47")	S7.560.500.000
11 - 17 mm (.43 - .67")	S7.560.600.000

*Intermateable with SpeedTEC® (Twilock-S)

7 - 12 mm (.24 - .47")	S7.566.500.00S
11 - 17 mm (.43 - .67")	S7.566.600.00S

M23 Power Panel Connector with Strain Relief, EMI, Male Thread

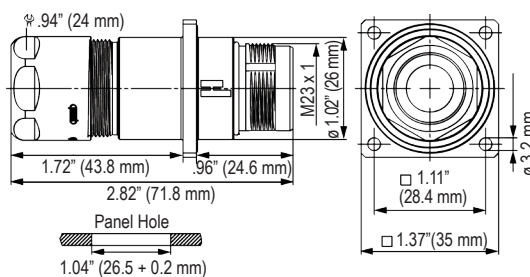


Cable-Ø

Part Number

Front or Rear Mounting, 4 x Holes Ø 3.2 mm, Flange 35 x 35 mm	S7.683.500.000
7 - 12 mm (.27 - .47")	S7.683.500.000
11 - 17 mm (.43 - .67")	S7.683.600.000

Flange 35 x 35 mm

M23 Power Panel Connector with Strain Relief, EMI, Female Thread

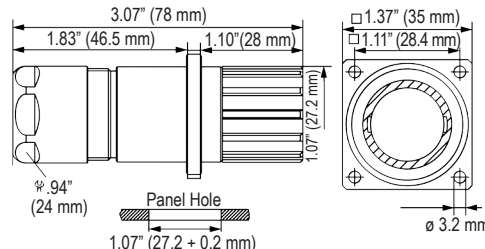

Cable-Ø

Part Number

Front or Rear Mounting, 4 x Holes Ø 3.2 mm, Flange 35 x 35 mm	S7.681.500.000
7 - 12 mm (.27 - .47")	S7.681.500.000
11 - 17 mm (.43 - .67")	S7.681.600.000

Flange 35 x 35 mm

MATES WITH TWILOCK SYSTEM DOES NOT MATE WITH TWILOCK SYSTEM