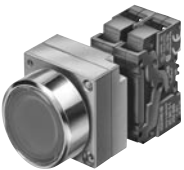


## Metal—Illuminated Momentary Pushbuttons


### Ordering Information

- ▶ Accessories see pages 516–521.
- ▶ Enclosures see page 523.
- ▶ Dimensions see pages 529–533.


### Complete Illuminated Pushbutton Unit—Flush

			With 1 NO Contact		With 1 NO + 1 NC Contact	
	Description	Color	Catalog No	Price \$	Catalog No	Price \$
 <p>Illuminated Pushbutton Unit with Flush Button</p>	Operating voltage 24V AC/DC with Integrated LED Block <b>NEW!</b>	red	3SB3646-0AB61 <sup>Ⓢ</sup>	48.15	3SB3647-0AB61	57.80
		yellow	3SB3645-0AA31	48.15	3SB3647-0AA31	57.80
		green	3SB3645-0AB71	48.15	3SB3647-0AB71	57.80
		blue	3SB3645-0AA51	48.15	3SB3647-0AA51	57.80
		white	3SB3645-0AA61	48.15	3SB3647-0AA61	57.80
		clear	3SB3645-0AA71	48.15	3SB3647-0AA71	57.80
	Operating voltage 120V AC with Integrated LED Block <b>NEW!</b>	red	3SB3650-0AB61 <sup>Ⓢ</sup>	48.15	3SB3651-0AB61	57.80
		yellow	3SB3657-0AA31	48.15	3SB3651-0AA31	57.80
		green	3SB3657-0AB71	48.15	3SB3651-0AB71	57.80
		blue	3SB3657-0AA51	48.15	3SB3651-0AA51	57.80
		white	3SB3657-0AA61	48.15	3SB3651-0AA61	57.80
		clear	3SB3657-0AA71	48.15	3SB3651-0AA71	57.80
	Operating voltage 24V AC/DC with BA 9s lampholder and 24 V LED	red	3SB3638-0AB61 <sup>Ⓢ</sup>	55.85	3SB3639-0AB61	65.50
		amber	3SB3637-0AA01	55.85	3SB3639-0AA01	65.50
		yellow	3SB3637-0AA31	55.85	3SB3639-0AA31	65.50
		green	3SB3637-0AB71	55.85	3SB3639-0AB71	65.50
		blue	3SB3637-0AA51	55.85	3SB3639-0AA51	65.50
		white	3SB3637-0AA61	55.85	3SB3639-0AA61	65.50
Operating voltage 120V AC with BA 9s lampholder and 120 V LED	red	3SB3642-0AB61 <sup>Ⓢ</sup>	55.85	3SB3643-0AB61	65.50	
	amber	3SB3641-0AA01	55.85	3SB3643-0AA01	65.50	
	yellow	3SB3641-0AA31	55.85	3SB3643-0AA31	65.50	
	green	3SB3641-0AB71	55.85	3SB3643-0AB71	65.50	
	blue	3SB3641-0AA51	55.85	3SB3643-0AA51	65.50	
	white	3SB3641-0AA61	55.85	3SB3643-0AA61	65.50	
with BA 9s lampholder <sup>Ⓢ</sup> less lamp	red	3SB3607-0AB61 <sup>Ⓢ</sup>	40.45	3SB3605-0AB61	50.10	
	amber	3SB3606-0AA01	40.45	3SB3605-0AA01	50.10	
	yellow	3SB3606-0AA31	40.45	3SB3605-0AA31	50.10	
	green	3SB3606-0AB71	40.45	3SB3605-0AB71	50.10	
	blue	3SB3606-0AA51	40.45	3SB3605-0AA51	50.10	
	white	3SB3606-0AA61	40.45	3SB3605-0AA61	50.10	
clear	3SB3606-0AA71	40.45	3SB3605-0AA71	50.10		

### Illuminated Pushbutton Actuator with Holder<sup>Ⓢ</sup>

	Color	Flush	Price \$	Extended		
					Price \$	
 <p>Illuminated Pushbutton Unit with Extended Button</p>	red	3SB3501-0AB61	14.10	3SB3501-0BB61	16.70	
	amber	3SB3501-0AA01	14.10	3SB3501-0BA01	16.70	
	yellow	3SB3501-0AA31	14.10	3SB3501-0BA31	16.70	
	green	3SB3501-0AB71	14.10	3SB3501-0BB71	16.70	
	blue	3SB3501-0AA51	14.10	3SB3501-0BA51	16.70	
	white	3SB3501-0AA61	14.10	—	—	
	clear	3SB3501-0AA71	14.10	3SB3501-0BA71	16.70	

### Illuminated Mushroom Actuator with Holder<sup>Ⓢ</sup>

	Color	30 mm Mushroom		40 mm Mushroom		60 mm Mushroom	
			Price \$		Price \$		Price \$
 <p>Mushroom-shaped Pushbutton, 60 mm</p>	red	3SB3501-1DB61	21.00	3SB3501-1GB61	21.00	3SB3501-1QB61	25.50
	amber	3SB3501-1DA01	21.00	3SB3501-1GA01	21.00	3SB3501-1QA01	25.50
	yellow	3SB3501-1DA31	21.00	3SB3501-1GA31	21.00	3SB3501-1QA31	25.50
	green	3SB3501-1DB71	21.00	3SB3501-1GB71	21.00	3SB3501-1QB71	25.50
	white	3SB3501-1DA61	21.00	3SB3501-1GA61	21.00	3SB3501-1QA61	25.50

<sup>Ⓢ</sup>Use of LED lamps is recommended.  
<sup>Ⓢ</sup>Red devices have 1 NC contact, instead of 1 NO.