

Product data sheet

Specifications



30mm Push Button, Type SK, selector switch, 2 position, black knob

9001SKS11B

Product availability: Stock - Normally stocked in distribution facility

Main

Range of Product	Harmony 9001SK
Product or Component Type	Head for selector switch
Device short name	9001SK

Complementary

Bezel material	Plastic
Mounting diameter	1.2 in (30 mm)
Operator position information	2 positions
Contacts type and composition	Without contact block
Device presentation	Basic element
Cap/operator or lens colour	Black
Operator profile	Standard handle
Type of operator	Stay put
Size	30 mm
Cam profile	5

Environment

Protective treatment	TC
Ambient Air Temperature for Storage	-40...158 °F (-40...70 °C)
Ambient Air Temperature for Operation	-13...158 °F (-25...70 °C)
Electrical shock protection class	Class II conforming to IEC 61140
IP degree of protection	IP66 IEC 60529
NEMA degree of protection	NEMA 1/2/3/3R/4/4X/6/12/13
Product Certifications	UL listed file E42259 CCN NKCR CSA LR24590 class 3211 03 CE

Ordering and shipping details

Category	US10CS121429
Discount Schedule	0CS1
GTIN	785901524366
Returnability	Yes

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Country of origin	US
-------------------	----

Packing Units

Unit Type of Package 1	PCE
------------------------	-----

Number of Units in Package 1	1
------------------------------	---

Package 1 Height	2.13 in (5.4 cm)
------------------	------------------

Package 1 Width	2.32 in (5.9 cm)
-----------------	------------------

Package 1 Length	2.91 in (7.4 cm)
------------------	------------------

Package 1 Weight	2.08 oz (59 g)
------------------	----------------

Unit Type of Package 2	S03
------------------------	-----

Number of Units in Package 2	120
------------------------------	-----

Package 2 Height	11.81 in (30 cm)
------------------	------------------

Package 2 Width	11.81 in (30 cm)
-----------------	------------------

Package 2 Length	15.75 in (40 cm)
------------------	------------------

Package 2 Weight	6.881 lb(US) (3.121 kg)
------------------	-------------------------

Contractual warranty

Warranty	18 months
----------	-----------

Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Environmental footprint

[Environmental Disclosure](#)

[Product Environmental Profile](#)

Use Better

Materials and Substances

Packaging made with recycled cardboard

Yes

Packaging without single use plastic

Yes

[EU RoHS Directive](#)

Pro-active compliance (Product out of EU RoHS legal scope)

REACH Regulation

[REACH Declaration](#)

California proposition 65

WARNING: This product can expose you to chemicals including: Nickel compounds, which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

Use Again

Repack and remanufacture

Circularity Profile

No need of specific recycling operations

Take-back

No

WEEE

 The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.

Offer Marketing Illustration

Product benefits / Features

Features
Harmony 9001SK



- 

Improved security thanks to finger-safe contact blocks and light modules
- 

Single screw Contact Block Fastening
- 

Robustness to withstand the harshest environments
- 

Automatic self-grounding operators without additional wiring
- 

Large metal set of accessories to customize your product

Offer Marketing Illustration

Product benefits / Features

Technical Benefits

Harmony 9001SK

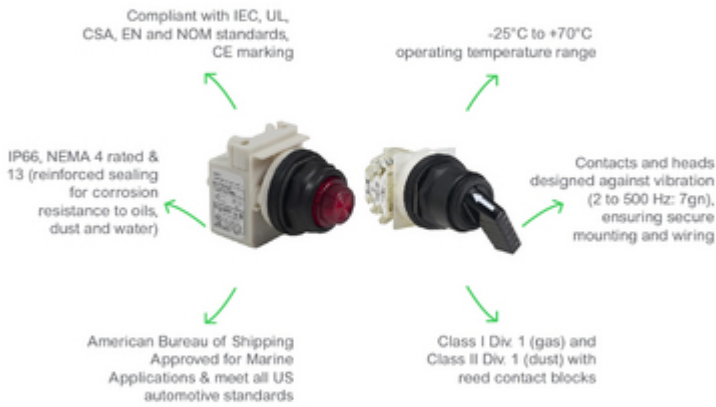


Image of product / Alternate images

Alternative



