

Product data sheet

Specifications



socket, Harmony Electromechanical Relays, for RXM2LB RXM4LB relays, 7A, screw clamp socket, mixed contact terminal

RXZE1M4C

Product availability: Non-Stock - Not normally stocked in distribution facility

Main

Range of Product	Harmony Electromechanical Relays
Product compatibility	Plug-in relay RXM 2 C/O Plug-in relay RXM 4 C/O
Device short name	RXZ
[Ith] conventional free air thermal current	7 A
Product or Component Type	Socket
Contacts type and composition	4 C/O

Complementary

[Ue] rated operational voltage	250 V AC IEC
Connections - terminals	Screw clamp terminals, 1 x 0.2...1 x 1.0 mm ² AWG 24...AWG 17) flexible with cable end Screw clamp terminals, 2 x 0.2...2 x 1.0 mm ² AWG 24...AWG 17) flexible with cable end Screw clamp terminals, 1 x 0.5...1 x 1.5 mm ² AWG 20...AWG 16) solid without cable end Screw clamp terminals, 2 x 0.5...2 x 1.5 mm ² AWG 20...AWG 16) solid without cable end
Tightening torque	< 0.8 N.m M3
Fixing mode	By screw (panel) Clip-on (35 mm symmetrical DIN rail)
Contact terminal arrangement	Mixed
[Uimp] rated impulse withstand voltage	4 kV
Overvoltage category	III
pollution degree	3
Sale per indivisible quantity	10
Width	1.1 in (29 mm)
Net Weight	0.117 lb(US) (0.053 kg)

Environment

Dielectric strength	2500 V
Standards	IEC 61984
Marking	CE
Ambient Air Temperature for Storage	-67...185 °F (-55...85 °C)

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Ambient Air Temperature for Operation	-40...131 °F (-40...55 °C)
---------------------------------------	----------------------------

Ordering and shipping details

Category	US1CP4B22153
Discount Schedule	CP4B
GTIN	03389119218481
Returnability	No
Country of origin	CN

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	1.14 in (2.9 cm)
Package 1 Width	1.22 in (3.1 cm)
Package 1 Length	2.95 in (7.5 cm)
Package 1 Weight	0.115 lb(US) (0.052 kg)
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Height	2.68 in (6.8 cm)
Package 2 Width	3.15 in (8.0 cm)
Package 2 Length	5.87 in (14.9 cm)
Package 2 Weight	1.193 lb(US) (0.541 kg)
Unit Type of Package 3	S03
Number of Units in Package 3	270
Package 3 Height	11.81 in (30.0 cm)
Package 3 Width	11.81 in (30.0 cm)
Package 3 Length	15.75 in (40.0 cm)
Package 3 Weight	32.8 lb(US) (14.9 kg)

Contractual warranty

Warranty	18 months
----------	-----------



Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Environmental footprint

Carbon footprint (kg CO2 eq, Total Life cycle) 1

Environmental Disclosure [Product Environmental Profile](#)

Use Better

Materials and Substances

Packaging made with recycled cardboard Yes

Packaging without single use plastic Yes

[EU RoHS Directive](#) Pro-active compliance (Product out of EU RoHS legal scope)

REACH Regulation [REACH Declaration](#)

California proposition 65 **WARNING:** This product can expose you to chemicals including: Nickel compounds, which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

Use Again


Repack and remanufacture

Circularity Profile No need of specific recycling operations

Take-back No

Connections and Schema

Wiring Diagram

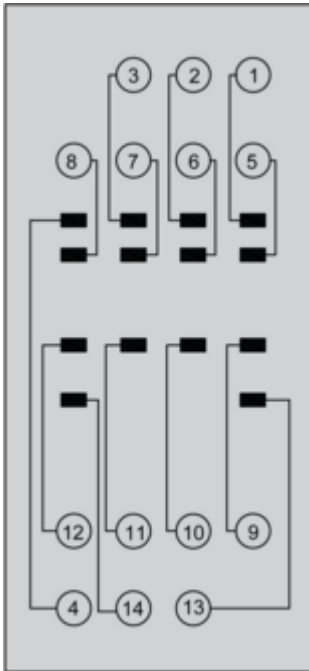

Technical Illustration

Dimensions

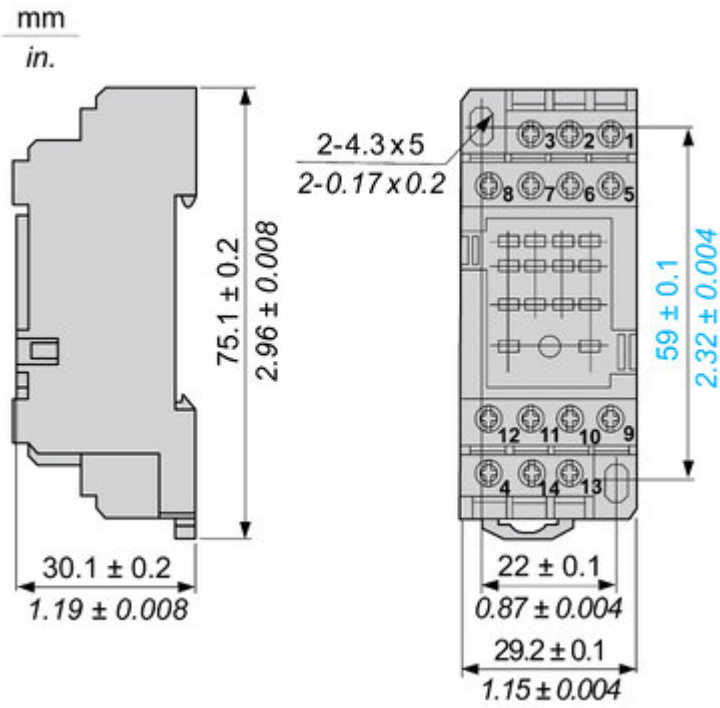


Image of product / Alternate images

Alternative







Image of product in real life situation

