

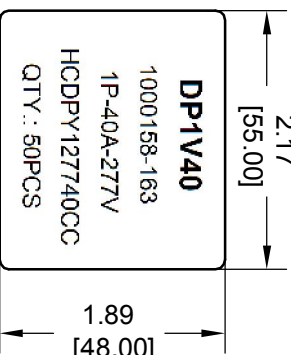
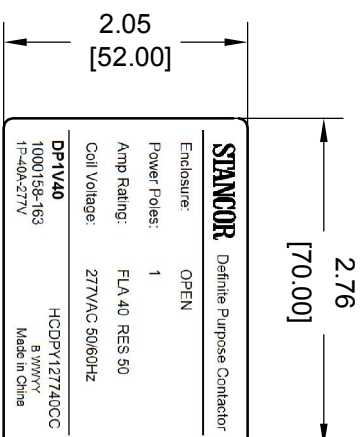
 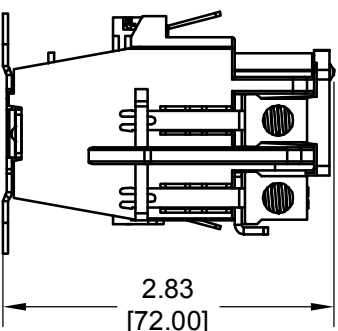


COIL DATA		NOTES: UNLESS OTHERWISE SPECIFIED
COIL 277VAC 50/60Hz		
2488 OHM 208 VAC OPERATE		
44-188 VAC DROPOUT		
30.8 VA INRUSH 5, 4 VA SEAL MAX VOLTAGE 304.7 VAC		

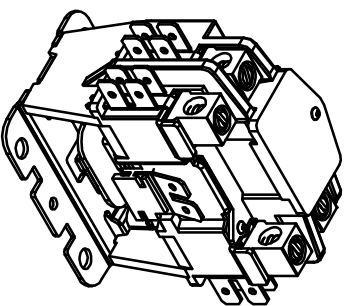

TOLERANCE	
INCHES [mm]	
X	±0.06 [1.50]
X.X	±0.02 [.50]
X.XX	±0.006 [.150]
X.XXX	±0.002 [.050]
ANGLES	±1°

REV					
	DESCRIPTION	ECN	DMN	APVD	APVD DATE
STANCOR 2425 South 21st Street Phoenix, AZ 85034 www.stancor.com (602)275-3800					
DRAWN BY	DRAWN DATE	CHECKED BY	CHECKED DATE		





STANCOR

DP1V40

T1	1000158-163	VAC	FLA LRA	L1
↑	1P-40A-277V	240/277	40 240	↑
	COLL	480	40 200	
T2	277VAC 50/60Hz	600	40 160	L2
↑	B wiring	RES AMP5.50		↓
	3 way	Herm. refig. comp.		
	E48485	HCCPY127740C		

Torque for CU 75°C: screws 20 in lbs, Nuts 40 in lbs

Product Label



STANCOR

Product Label

Master Carton Label