
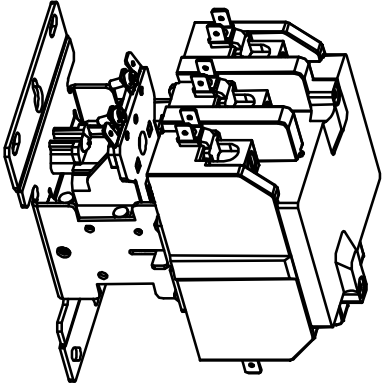
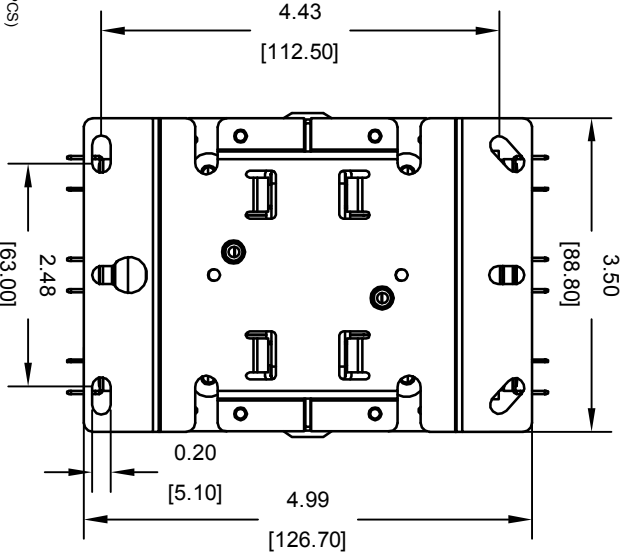
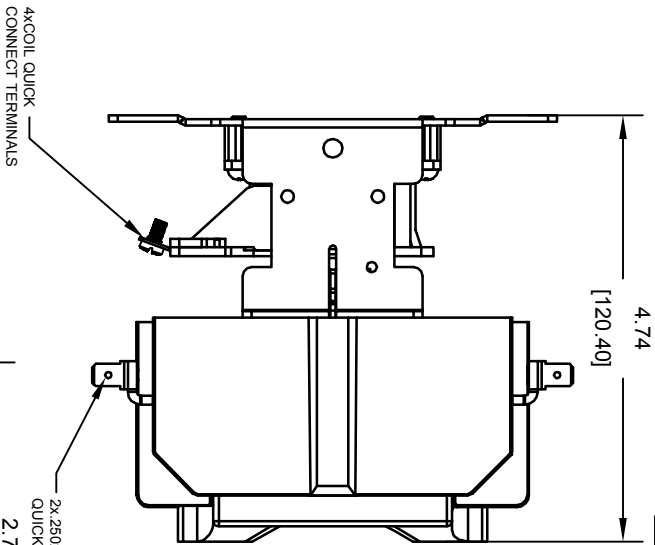


POLES	COIL VAC	FLA	RES	TERMINATION	COVER	INDIVIDUAL BOX
3	277VAC 50/60Hz	75	90	#14-1 COMPRESSION TERMINALS 2 Quick Connect Power Termination	YES	YES

COIL DATA
COIL 277VAC 50/60Hz- 120 OHM 208 VAC OPERATE 44.3-183.9VAC DROP-OUT 639 VA INRUSH #13 VA SEAL MAX VOLTAGE 304.7 VAC

NOTES: UNLESS OTHERWISE SPECIFIED

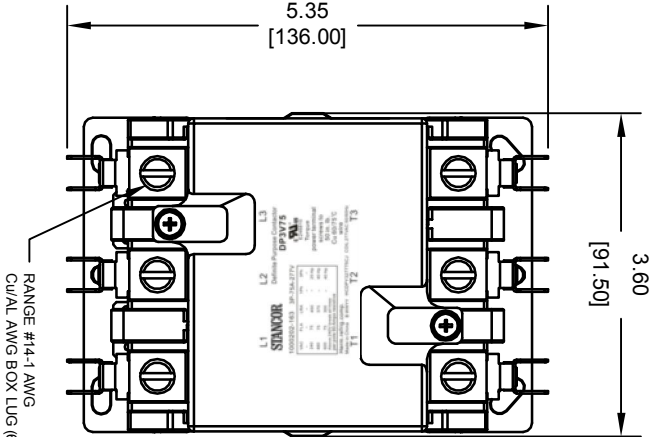

L1	L2	L3
STANCOR	Definite Purpose Contactor	DP3V75
1000202-163	3P-75A-277V	
VAC	FLA	LRA
240	75	450
480	75	375
600	75	300
50/60Hz		
per pole 50 Amps resistive		
Herm rating comp.		
Made in China	B W W Y Y	HCDPY32775CJ
T1	T2	T3

Product Label

STANCOR	Definite Purpose Contactor
Enclosure:	OPEN
Power Poles:	3
Amp Rating:	FLA 75 RES 90
Coil Voltage:	277VAC 50/60Hz
DP3V75	HCDPY32775CJ
1000202-163	B W W Y Y
3P-75A-277V	Made in China

Individual Box Label

STANCOR	Definite Purpose Contactor
Enclosure:	OPEN
Power Poles:	3
Amp Rating:	FLA 75 RES 90
Coil Voltage:	277VAC 50/60Hz
DP3V75	HCDPY32775CJ
1000202-163	B W W Y Y
3P-75A-277V	Made in China

Master Carton Label

TOLERANCE	
INCHES [mm]	
X	±0.06 [1.50]
X.X	±0.02 [1.50]
X.XX	±0.006 [1.50]
X.XXX	±0.002 [1.50]
ANGLES	±1°

THIRD ANGLE PROJECTION



REV.					
	DESCRIPTION	ECN	OWN	APPD	APPD DATE
STANCOR 2425 South 21st Street Phoenix, AZ 85034 (602)275-3800 www.stancor.com					
DRAWN BY	DRAWN DATE		CHECKED BY		CHECKED DATE
DESC.		3P-75A-277V		PAGE 1 OF 1	
PART NO. DP3V75					